



### MightyRods PRO GLO Cable Rod 6mm Pk1

A flexible 6mmØ rod, this phosphorescent GLO rod guides the way when routing in low light conditions.

Item Number	Ø	i	i	📦
T5432	6mm	Flexible	Phosphorescent	1



### MightyRods PRO SpiraFLEX Cable Rod 4mm Pk1

This super flexible 4mm Ø rod is the perfect solution when access is tight or when navigating around obstacles. The innovative helical profile and PET material reduces friction and minimises snagging.

Item Number	Ø	i	📦
T5433	4mm	Super-flexible	1




### MightyRods 7pc Standard Kit Accessory Pack

A full range of accessories from the MightyRods PRO Standard Kit.

CONTENTS:  
Flexi Lead, Hook, Ring, Gender Changer, Flat Bullet, In-line Swivel and Domed Bullet.

Item Number	i	📦
T5440	7 piece	1

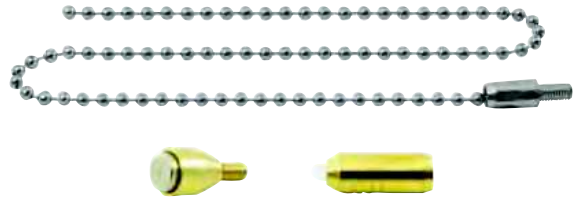


### MightyRods 3pc Super Kit Accessory Pack

Upgrade your MightyRod kit with this Super Kit Upgrade Pack.

CONTENTS:  
Torch, Magnet and Chain.

Item Number	i	📦
T5441	3 piece	1

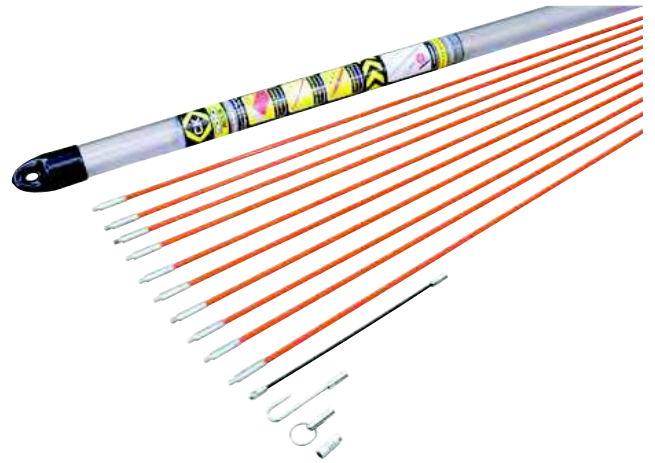

### MightyRods 10m Cable Rod Set

'Mighty-Fix' zinc plated steel connectors are glued, indented and crimped for ultimate tensile strength in excess of 375kg. Slimline connectors reduce snagging and provide accessibility through smaller holes. 5mmØ rods offer the optimal balance of rigidity and flexibility for the majority of cable routing requirements. High sheen fibreglass and resin composite rods minimise snagging and splintering.

CONTENTS:  
10 x 1m rods, cable hook, 190mm coiled steel flexi lead, mini eye & ring, 5mm adapter.

Item Number	↔	📦
T5410	10 x 1m	6

## C.K HEAD TORCHES



## C.K HAND TORCHES




### C.K LED HEAD TORCH 200 LUMENS

POWERFUL AND ROBUST, THE FEATURE PACKED C.K T9620 IS A TRULY ASTOUNDING PROFESSIONAL QUALITY HEAD TORCH.

#### SPECIFICATION:

- High Power 200 Lumen Cree XM-L T6 LED
- 3 lighting modes: high, dimmed, flash
- One-handed rapid slide focus mechanism - spot (x1) to flood (x7)
- Beam intensifying plano-convex optical lens
- Robust high grade aluminium lamp body
- Adjustable head lamp swivels through 90°
- Detachable head lamp & battery pack
- Water & dirt resistant, tested to IP64
- Battery life: high - 5hrs, dimmed - 12hrs


200 LUMENS

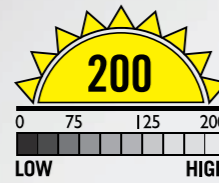

Item No: T9620

SPOT : FLOOD	MAX RANGE	WEATHER RATING	IMPACT RESISTANT	POWER SUPPLY	BATTERY LIFE
X1: X7	250M	IP64	1M	4 x AA (not included)	UP TO 12 HOURS

120 LUMENS

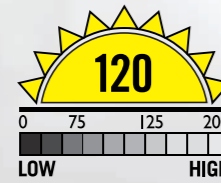

Item No: T9610

SPOT : FLOOD	MAX RANGE	WEATHER RATING	IMPACT RESISTANT	POWER SUPPLY	BATTERY LIFE
X1: X7	200M	IP64	1M	3 x AAA (not included)	UP TO 13 HOURS

### C.K LED HEAD TORCH 120 LUMENS

COMPACT AND LIGHTWEIGHT, THE C.K T9610 IS A REMARKABLY POWERFUL HEAD TORCH FOR ITS SIZE.

#### SPECIFICATION:

- High Power 120 Lumen Cree XR-E Q3 LED
- 3 lighting modes: high, dimmed, flash
- One-handed rapid slide focus mechanism - spot (x1) to flood (x7)
- Beam intensifying plano-convex optical lens
- Robust high grade aluminium lamp body
- Adjustable head lamp swivels through 90°
- Water & dirt resistant, tested to IP64
- Battery life: high - 5hrs, dimmed - 13hrs


### C.K LED HAND TORCH 150 LUMENS

AN IMMENSELY VERSATILE HIGH PERFORMANCE HAND TORCH, THE C.K T9520 HAS AN IMPRESSIVE 250M RANGE SPOT BEAM AND AN EXTENSIVE X30 FLOOD BEAM.

#### SPECIFICATION:

- High Power 150 Lumen Cree XR-E Q5 LED
- 3 Lighting modes: high, dimmed, flash
- One-handed rapid slide focus mechanism - spot (x1) to flood (x30)
- Beam intensifying plano-convex optical lens
- Robust high grade aluminium body
- Water & dirt resistant, tested to IP64
- Battery life: high - 5hrs, dimmed - 14hrs
- Size: 133 x 40mm


150 LUMENS

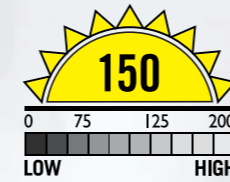

Item No: T9520

SPOT : FLOOD	MAX RANGE	WEATHER RATING	IMPACT RESISTANT	POWER SUPPLY	BATTERY LIFE
X1: X30	250M	IP64	1M	3 x AAA (not included)	UP TO 14 HOURS

120 LUMENS

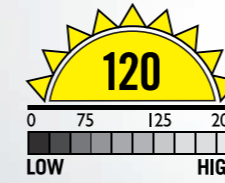

Item No: T9510

SPOT : FLOOD	MAX RANGE	WEATHER RATING	IMPACT RESISTANT	POWER SUPPLY	BATTERY LIFE
X1: X10	150M	IP64	1M	3 x AAA (not included)	UP TO 16 HOURS

### C.K LED HAND TORCH 120 LUMENS

COMPACT YET POWERFUL, THE C.K T9510 ALSO HAS A DIMMED BEAM MODE FOR GLARE-FREE CLOSE PROXIMITY USE.


#### SPECIFICATION:

- High Power 120 Lumen Cree XR-E Q5 LED
- 3 Lighting modes: high, dimmed, flash
- One-handed rapid slide focus mechanism - spot (x1) to flood (x10)
- Beam intensifying plano-convex optical lens
- Robust high grade aluminium body
- Water & dirt resistant, tested to IP64
- Battery life: high - 6hrs, dimmed - 16hrs
- Size: 107 x 30mm

HIGH POWER CREE LED HAND TORCHES



FEATURES: Rapid slide focus mechanism

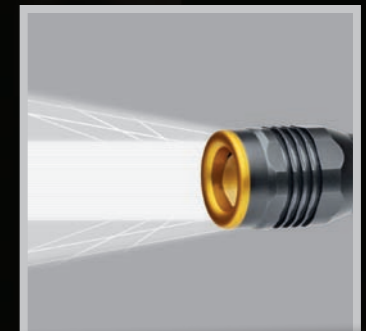

FEATURES: Plano-convex optical lens

HIGH POWER CREE LED HEAD TORCHES