

PRODUCT SPECIFICATION

Brand	C.K
Product Range	S2 Screwdriver bits sets
Catalogue number	4501, 4502, 4508, 4509, 4517, 4518, 4520, 4521, 4522, 4523, 4524, 4525, 4527, 4528, 4566, 4569, 4583
Date	03/02/2015

Range Description

A range of professional quality screwdriver bits sets

Features

- Premium quality S2 alloy steel for exceptional strength & durability
- Precision machined tip for an exact fit & damage free screwdriving

Contents:

4502 – 31 set – Contents: PZ1 x1, PZ2 x4, PZ3 x1, PH1 x1, PH2 x2, TX10 x2, TX15 x4, TX20 x4, TX25 x2, TX30 x2, TX40 x1, Slotted 4,0 x1, 5,5 x1, 6,5 x1, Hex4 x1, Hex5 x1, Hex6 x1, Screwdriver bit holder x1

4501 – TX10 x1, TX15 x1, TX20 x1, TX25 x1, TX30 x1, TX40 x1, Screwdriver bit holder x1

T4517 - PZ1 x1, PZ2 x4, PZ3 x1



T4502



T4501




T4517

4520 – 4 bit sets Cat No. 4521, 4522, 4523 & 4524 plus 4570 bit driver



4520

4521 – Slotted 3, 4, 4.5, 5, 6, 7, 8 & 9mm

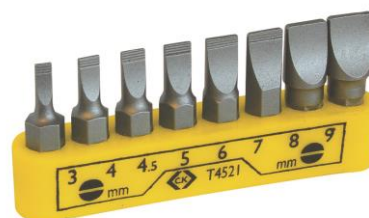


4521

4522 – PH 0, 1, 2, & 3 + PZD 0, 1, 2, & 3



4522

4523 – TX 8, 10, 15, 20, 25, 27, 30 & 40

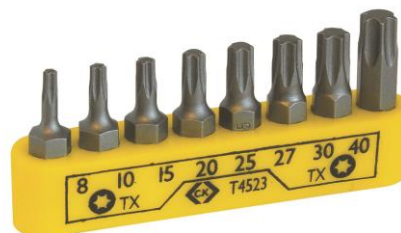

4523

4524 – Hex 1.5, 2, 2.5, 3, 4, 5, 5.5 & 6mm

4525 – Slotted 4, 5, & 7mm + PH 1, 2 & 3 + PZD1, 2 & 3 + TX 15 & 20



4524

4527 – TX Tamperproof 8, 10, 15, 20, 25, 27, 30 & 40



4525

4528 – Hex Tamperproof 2, 2.5, 3, 4, 5, 5.5, 6 & 7mm



4527

4509 – 41 piece set - Contents: PH1 x2, PH2 x4, PH3 x2, PZ1 x4, PZ2 x8, PZ3 x4, Slotted 4mm x2, 5.5mm x2, 6mm x2, 8mm x2, TX15 x1, TX20 x1, TX25 x1, TX30 x1, Hex3 x1, Hex4 x1, Hex5 x1, Hex 6 x1
Screwdriver bit holder x1



4528

4508 – 41 piece set

- ⊕ PH0 x1, PH1 x1, PH2 x3, PH3 x1
- ⊕ PZ0 x1, PZ1 x1, PZ2 x1, PZ3 x1
- ⊖ 4.0mm x1, 5.0mm x1, 6.0mm x1, 8.0mm x1
- ⊙ Size 4x1, Size 5x1, Size 6x1, Size 8x1
- ⊙ Size 4x1, Size 6x1, Size 8x1, Size 10x1
- ⊕ Size 6x1, Size 8x1, Size 10x1
- ⊙ TX8 x1, TX10 x1, TX15 x1, TX20 x1, TX25 x1, TX27 x1, TX30 x1, TX40 x1
- ⊙ Size 1x1, Size 2x1, Size 3x1, Size 4x1
- ⊙ Size 1x1, Size 2x1, Size 3x1
- ⊖ Screwdriver Bit Holder x1

4566 – (Discontinued) Slotted 4.5, 5.5, 6.5 + PH (three of each) 1, 2, & 3 + PZD (three of each) 1, 2 & 3 + TX 10, 15, 20, 25, 30 & 40 + Hex 3, 4 & 5 + bit driver 4570

4569 – TiN PZD 1, 2 (4 off) & 3 + 4570 bit driver

4583 - Slotted 5.5 & 6.5mm + PH 1 & 2 + PZD 1 & 2 + 4570 bit driver



T4509



T4508



4566



4569



4583

Item Number	Item Description	EAN No	Commodity code	Carton Qty
T4501	Screwdriver Bit Set of 7 – TX	5013969996807	82079030	12
T4502	Screwdriver Bit Set of 31 – Mixed	5013969996814	82079030	6
T4508	Screwdriver Security Bit Set of 41 – Mixed	5013969996616	82079030	6
T4509	Screwdriver Bit Set of 41 – Mixed	5013969996623	82079030	6
T4517	Screwdriver Bit Set of 7 – PZ	5013969996784	82079030	12
T4518	Screwdriver Bit Set of 7 – PH	5013969996791	82079030	12
T4520	Screwdriver bit set (25mm) 33 Pce *	5013969004984	82079030	6
T4521	Screwdriver Bit set in clip Slotted 8 Pce *	5013969004977	82079030	6
T4522	Screwdriver Bit set in clip PH/PZD 8 Pce *	5013969004960	82079030	6
T4523	Screwdriver Bit set in clip TX 8 Piece	5013969004953	82079030	6
T4524	Screwdriver Bit set in clip Hex 8 Piece	5013969004946	82079030	6
T4525	Screwdriver Bit set (100mm) 10 Pcs *	5013969004939	82079030	6
T4527	Screwdriver Bit set in clip TX T/Proof	5013969025675	82079030	6
T4528	Screwdriver Bit set in clip Hex T/Proof	5013969025668	82079030	6
T4566	Screwdriver Bit Set 31pce *	5013969978049	82079030	20
T4569TINC	Screwdriver bit set PZD Bits TIN Carded *	5013969035933	82079030	20
T4583C	Screwdriver bit set Assorted Bits Carded *	5013969171105	82079030	20

Technical product information	
Standards compliance	
User health and safety information	Users and bystanders are advised to wear safety goggles
RoHS/WEEE compliance	This product range does not fall within the scope of RoHS or WEEE regulations
Material safety data	None applicable
Warranty	C.K Drill bits are guaranteed for life against imperfect materials or workmanship Normal wear and tear or damage caused through inappropriate use is not covered

Country of origin	4566, 4569, 4583 – Germany All other – Taiwan
-------------------	--

Dimensional details

Item	Product only				Product on primary packaging			
	Width mm	Depth mm	Height mm	Net weight g	Width mm	Depth mm	Height mm	Gross weight g
T4501	71	21	81	93	-	-	-	-
T4502	100	28	130	291	-	-	-	-
T4508	140	37	76	313	180	50	200	359
T4509	140	37	76	313	180	50	200	359
T4517	71	21	81	93	-	-	-	-
T4518	71	21	81	93	-	-	-	-
T4520	-	-	-	-	105	20	220	228
T4521	-	-	-	-	90	20	110	56
T4522	-	-	-	-	90	20	110	56
T4523	-	-	-	-	90	20	110	56
T4524	-	-	-	-	90	20	110	56
T4525	-	-	-	-	110	15	170	274
T4527	-	-	-	-	90	20	110	56
T4528	-	-	-	-	90	20	110	56
T4566	-	-	-	-	80	120	30	328
T4569TINC	-	-	-	-	82	18	113	90
T4583C	-	-	-	-	82	18	113	90

Item	Shelf box (secondary packaging)				Euro Pallet data Wi x Hi	
	Width mm	Depth mm	Height mm	Gross weight g	No of cartons on base	Number of rows high
T4501	95	270	60	1186		
T4502	105	360	70	1855		
T4508	195	215	240	2270		
T4509	195	215	240	2270		
T4517	95	270	60	1186		
T4518	95	270	60	1186		
T4520	110	120	230	1425		
T4521	120	95	63	370		

T4522	120	95	63	370		
T4523	120	95	63	370		
T4524	120	95	63	370		
T4525	85	120	182	1705		
T4527	120	95	63	370		
T4528	120	95	63	370		
T45660	180	320	180	6770		
T4569TINC	95	330	85	1890		
T4583C	95	330	85	1890		

Packaging waste details

Item	Primary Packaging				Secondary packaging			
	Plastic g	Use	Card g	Use	Plastic g	Use	Card g	Use
T4501	-	-	-	-			70	Carton
T4502	-	-	-	-			109	Carton
T4508	44	Blister	2	Card			116	Carton
T4509	44	Blister	2	Card			116	Carton
T4517	-	-	-	-			70	Carton
T4518	-	-	-	-			70	Carton
T4520	20	Blister	12	Card			74	Carton
T4521	4	Blister	6	Card			30	Carton
T4522	4	Blister	6	Card			30	Carton
T4523	4	Blister	6	Card			30	Carton
T4524	4	Blister	6	Card			30	Carton
T4525	8	Blister	10	Card			56	Carton
T4527	4	Blister	6	Card			30	Carton
T4528	4	Blister	6	Card			30	Carton
T4566	40	Bags	-	-			170	Carton
T4569TINC	4	Hanger	-	-			98	Carton
T4583C	4	Hanger	-	-			98	Carton