

MILAN S.r.l. a socio unico


Head Office – Export department:
 Viale Europa, 74
 20090 Cusago (MI) Italy
 T. +39 02 9039.4556-4158
 F. +39 02 9039.4551
 www.taskercables.com

Ufficio Commerciale e Centro Distribuzione
 Viale Europa 72 Strada F12
 20090 Cusago (MI) Italy
 T. +39 02 9039.0037-0059
 F. +39 02 9039.0049
 www.tasker.it




Technical Datasheet

tasker® C295 - 4x0,22 mm² - Alarm Cable

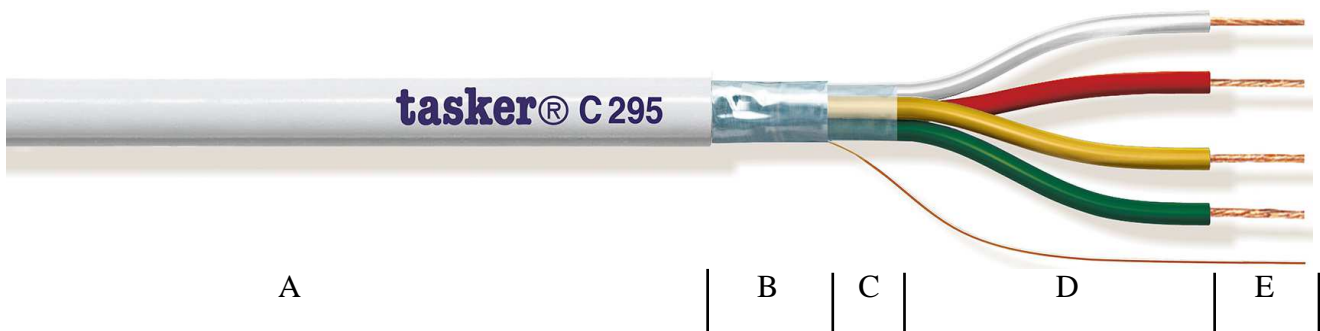

CATEGORY

Alarm Cable (See Data Network Catalogue).

- A:** White Soft Flame Retardant **PVC** Sheath - RAL 9003.
Outer cable Ø: 3,80 (±0,20) mm.
- B:** Shielding with Aluminum polyester tape covering 100%
+ Drain Wire in O.F.C. red copper.
- C:** The four conductors are stranded together with polyester based tape.
- D:** Insulation with PVC – Diam. Ø 1,00 (±0,20) mm.
Core colors: White, Red, Yellow and Green.
- E:** Stranded formation of 7x0,20 mm in O.F.C. Red Copper .
Nom. Cross section 4x0,22 mm².

MARKING

tasker® C295 4X2X0,22 ALARM SYSTEMS cable FirestoP®- CEI UNEL 36762 C-4/U 400V MADE IN ITALY

CUSTOM

This product is also available in **L.S.Z.H., PE, PUR**, with or without **Steel Armor**.

Cable Properties

Conductor Resistance	90 Ω/Km ± 5%
Max Rated Voltage	150 V
Operative Temperature	-20/+70°C

USE	<input checked="" type="checkbox"/>	Indoor	Interno Edificio	INSTALLATION	<input checked="" type="checkbox"/>	Fixed	Fissa	INFORMATION	<input checked="" type="checkbox"/>	RoHS2 Compliant
Impiego	<input checked="" type="checkbox"/>	Outdoor Limited	Esterno Limitato	Posa	<input checked="" type="checkbox"/>	Flexible Limited	Flessibilità limitata	Informazioni	<input checked="" type="checkbox"/>	Ver. C / 27.06.16
		Outdoor Direct Burial	Esterno Interrato		<input checked="" type="checkbox"/>	Dynamic (Drag Chain)	Mobile in Catena			
				Dynamic (Torsion)	Mobile in Torsione			