


Film, Metallized Polypropylene, DC Link, C4DE, 220 uF, 10%, 600 V

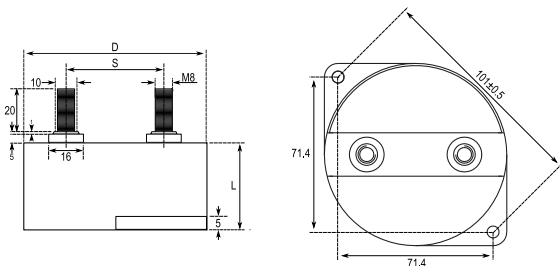

Dimensions

D	84mm +/-0.5mm
L	64mm +/-2mm
S	45mm +/-1mm
LL	20mm NOM

Packaging Specifications

Mounting:	Flange Mount
Packaging:	Bulk
Packaging Quantity:	12

General Information

Dielectric:	Metallized Polypropylene
Style:	Can
Series:	C4DE
RoHS:	Yes
Lead:	Threaded Studs M8
Miscellaneous:	38 Amps (10kHz, 85C)

Specifications

Capacitance:	220 uF
Capacitance Tolerance:	10%
Voltage DC:	600 VDC
Temperature Range:	-40/+85C
Rated Temperature:	85C
Max dVdt:	20 V
Resistance:	1 mOhms (10kHz)
Current:	100 Amps (10kHz 25C), 85 Amps (10kHz 45C), 65 Amps (10kHz 65C)
Inductance:	40 nH