

# HAND HELD CASES

UNIVERSAL ENCLOSURES

HAND HELD CASES

HEAVY DUTY ENCLOSURES

DIN RAIL ENCLOSURES

INTERFACE SUPPORTS

ELECTRICAL ENCLOSURES

DIECAST & METAL ENCLOSURES

DESKTOP & INSTRUMENT CASES

MULTI-PURPOSE & POTTING BOXES

19" ENCLOSURES

19" CABINETS

DEVELOPMENT BOARD ENCLOSURES

CUSTOM SIZED ENCLOSURES

FSPT/CUSTOM SERVICES

## 66 Series Grip Cases



Innovative unique design for quick and easy assembly. Features soft-grip corners for added protection and ergonomic feel.

- Moulded in high impact ABS, UL94-V0
- Screwless assembly via four soft-grip corners
- Battery compartment lid with M3 retaining screw
- Optional retaining screws for added security
- Recesses in lid and base for membrane keypads or overlays
- PCB pillars in lid and base
- Optional EPDM gasket for IP65 seal



### SPECIFICATION

Materials	Base & lid, front and back panels high impact ABS, UL94-V0. Soft-grip corners TPE coated polypropylene
Operating temperature	Resistant to temperatures of up to 85°C
Protection class	IP62 as standard IP65 with gasket option
Standard colours	Lid, base and panels light grey or black Soft-grip corners red, blue, yellow, green, orange, grey or black Custom colours available to order
Standard unit includes	25mm high Lid, base & panels 35mm high Lid, base & panels Battery door & retaining screw Soft-grip corners and battery compartment supplied separately

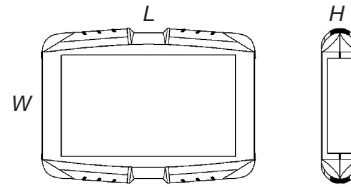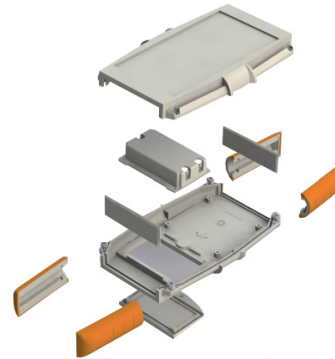

### Battery Compartments

TYPE NO.	DESCRIPTION	COLOUR
CHHBAT1BK	Clip-in battery compartment PP3	Black
CHHBAT1GY	Clip-in battery compartment PP3	Grey
CHHBAT2BK	Clip-in battery compartment AA	Black
CHHBAT2GY	Clip-in battery compartment AA	Grey



### 66 Series IP65 Gasket

- EPDM rubber gasket
- IP65 protection
- Operating temperature -20°C to +85°C

TYPE NO.	DESCRIPTION
CHH66GSKT	66 Series IP65 Gasket

BLACK	LIGHT GREY	LENGTH	WIDTH	HEIGHT	STYLE
CHH661NBK	CHH661NGY	145mm	95mm	25mm	-
CHH661BBK	CHH661BGY	145mm	95mm	25mm	Battery door
CHH662NBK	CHH662NGY	145mm	95mm	35mm	-
CHH662BBK	CHH662BGY	145mm	95mm	35mm	Battery door
CHH663NBK	CHH663NGY	185mm	110mm	25mm	-
CHH663BBK	CHH663BGY	185mm	110mm	25mm	Battery door
CHH664NBK	CHH664NGY	185mm	110mm	35mm	-
CHH664BBK	CHH664BGY	185mm	110mm	35mm	Battery door
CHH665NBK	CHH665NGY	200mm	120mm	25mm	-
CHH665BBK	CHH665BGY	200mm	120mm	25mm	Battery door
CHH666NBK	CHH666NGY	200mm	120mm	35mm	-
CHH666BBK	CHH666BGY	200mm	120mm	35mm	Battery door

\* soft grip corners sold separately



### Soft-Grip Corners

TYPE NO.	COLOUR	DESCRIPTION
CHH66C1BL	Blue - RAL 5007	To fit 25mm high cases
CHH66C1GR	Green - RAL 6026	To fit 25mm high cases
CHH66C1RD	Red - RAL 3020	To fit 25mm high cases
CHH66C1OR	Orange - RAL 2003	To fit 25mm high cases
CHH66C1BK	Black - RAL 9004	To fit 25mm high cases
CHH66C1YL	Yellow - RAL 1021	To fit 25mm high cases
CHH66C1GY	Grey - RAL 7001	To fit 25mm high cases
CHH66C2BL	Blue - RAL 5007	To fit 35mm high cases
CHH66C2GR	Green - RAL 6026	To fit 35mm high cases
CHH66C2RD	Red - RAL 3020	To fit 35mm high cases
CHH66C2OR	Orange - RAL 2003	To fit 35mm high cases
CHH66C2BK	Black - RAL 9004	To fit 35mm high cases
CHH66C2YL	Yellow - RAL 1021	To fit 35mm high cases
CHH66C2GY	Grey - RAL 7001	To fit 35mm high cases