



## Portable SSD DS72


# Unleash Your Imagination, Experience the Epic Adventure



Introducing the DS72, a revolutionary device that incorporates SSD technology, enabling you to transfer data swiftly and efficiently. With its compatibility for both Type A and Type C connectors, you can connect a wide range of devices. Utilizing its impressive transfer speed and adaptable form factor, the DS72 becomes an indispensable companion for maximum productivity.



**High-speed Transfers**

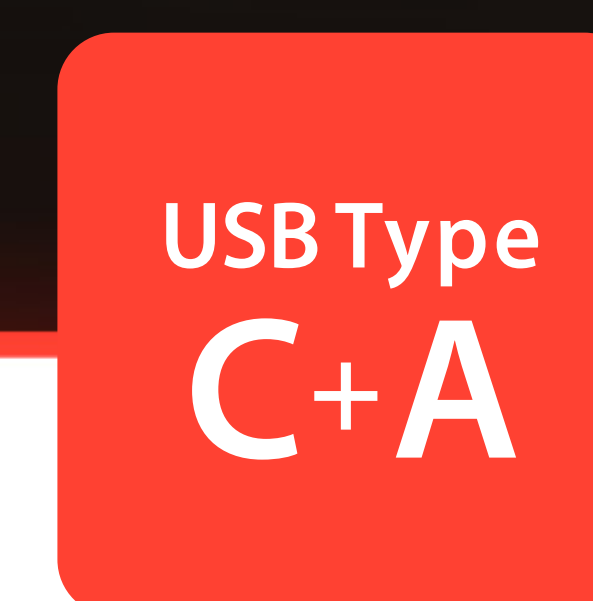

**Dual Interface**



**Ample Capacity**

### Features

- Impressive read speeds of up to 1,050MB/s and write speeds of up to 850MB/s
- Sturdy metal housing featuring a convenient flip cap design
- Easy Plug & Play use
- Includes Recuva File Recovery for effortless file retrieval
- Comes with free SP Widget software for backup, restore, AES 256-bit encryption, and cloud storage

### Specifications

Capacity	250GB, 500GB, 1TB
Dimensions	80.9 x 21.3 x 10.4 mm
Weight	15.6g
Material	Aluminum + Rubber
Color	Black
Sequential Read/Write (max.)	Up to 1050/850 MB/s
Interface	USB Type-A and USB Type-C 3.2 Gen 2 (USB 3.1 Gen 2, USB 3.1 Gen 1 & USB 3.0 & USB 2.0 backwards-compatible)
OS Compatibility	PC- Windows 11/10/8.1/8/7/Vista/XP, Mac OS 10.3.x or later, Linux 2.6.x or later Mobile device- Android OS 6.0 or later, iOS 13 or later
Operating Temperature	0°C - 70°C
Certification	CE, UKCA, FCC, BSMI
Warranty	5-year limited warranty

### Ordering Information

Capacity	Part Number
250GB	SP250GBUC3S72V1K
500GB	SP500GBUC3S72V1K
1TB	SP001TBUC3S72V1K

