





52.622

## Viewmate monitor arm - desk 622


With each of the four arms being height and depth adjustable, this monitor arm makes a great quadruple monitor set-up. The clamp levers make height adjustment a breeze. An ergonomic design that is robust, cost-effective and easy to use.

- Static height adjustment
- Independent depth adjustment
- Fitted with cable covers and cable loop ties to guide cables tidily
- Main components made of steel
- VESA MIS-D 75 x 75/100 x 100 mm compatible
- Monitor: tilt +90°/-90°, swivel +90°/-90°, rotate 360°
- Arm: swivel +90°/-90°
- Weight capacity max. 12 kg (26,5 lb) per monitor
- Comes with a desk clamp mount and bolt-through desk mount
- Suitable for a desktop thickness of 5 up to 40 mm (0,2" - 1,6") (clamp) or 50 mm (2,0") (bolt through)
- Monitor size limit: width 874 mm (34,4") - height 477 mm (18,8")
- Easy to adjust in height using a clamp lever

# viewmate <sup>x</sup>

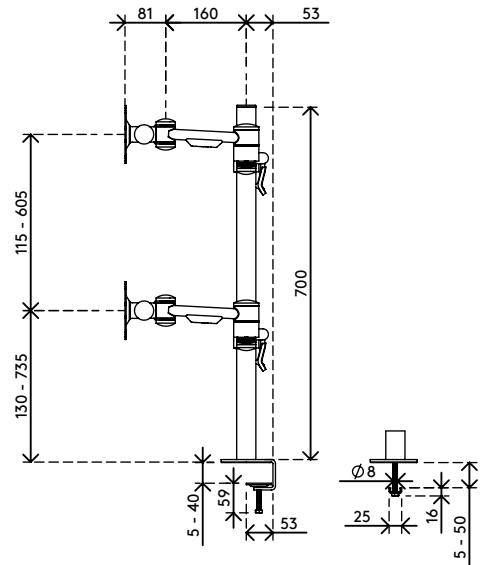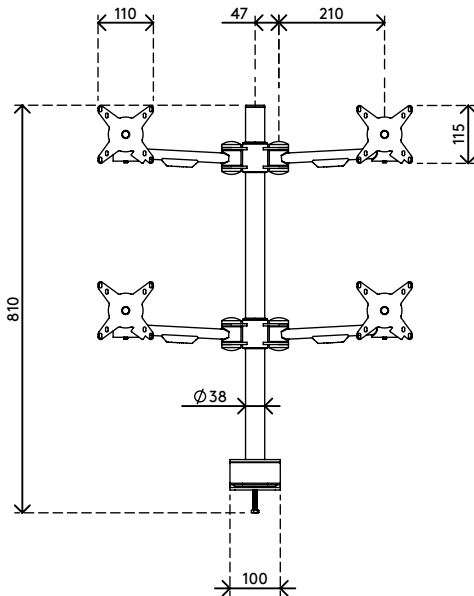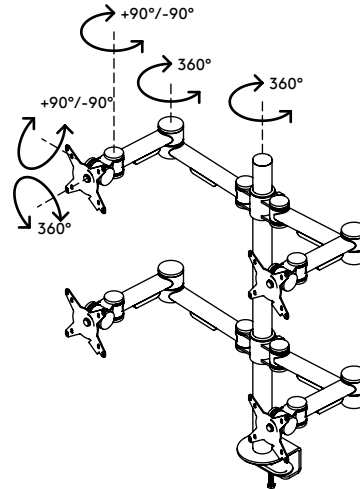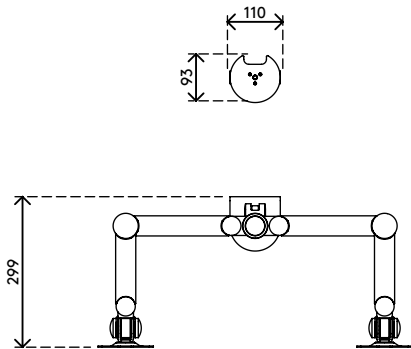

+90°/-90°

 


+90°/-90°



360°



 874 mm (34,4")



477 mm (18,8")



75 x 75/100 x 100



(4x) 12 kg (26,5 lb)

## Viewmate monitor arm - desk 622

2020/10/06


# 52.622

 995 x 305 x 105 mm

 1 pcs

 silver

 10,4 kg

 805410526221