


Epson TM-T88VII (132): USB, Ethernet, PoweredUSB, Black

DATASHEET / BROCHURE

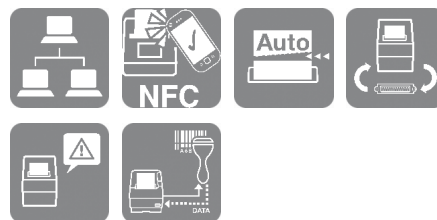

Market-leading¹, high-performance and eco-conscious receipt printers, backed by proven reliability

The TM-T88VII is our new high-performance receipt printer range. It features a range of design, connectivity and usability improvements and enhancements to improve the user experience.

Reliable and high-performance

Avoid downtime by choosing proven, reliable hardware from the market leader¹. Fast print speeds of 500mm/s and high-quality, printed legible receipts will ensure happy customers.

Backwards compatible

The TM-T88VII is fully compatible with the existing T88V and T88VI software so there are no expensive costs associated with changing business infrastructure. The printer also has same footprint as previous models, meaning no additional costs of having to change the counters/tills.

Eco-conscious

The TM-T88VII demonstrates reduced environmental impacts, with lower noise level, lower power consumption and smaller, more efficient power supply. The printer is now compatible with more eco-friendly, Phenol-free paper.

KEY FEATURES

- **Reliable hardware**
Backed by our tried and trusted build quality
- **High performance**
Max print speed 500mm/s
- **Connectivity and interface options**
USB, Ethernet, USB Host as standard; serial, PoweredUSB, options
- **Backwards compatible**
Fully compatible with the existing T88V and T88VI software
- **Reduced environmental impacts**
Low power consumption, support for Phenol-free paper

PRODUCT SPECIFICATIONS

OTHER FEATURES

Preloaded SW Server Direct Print, ePOS-Device®, ePOS-Display, ePOS-Print®

PAPER

Paper size 79.50 ± 0.50 (W) mm x dia 83.00 mm,
57.50 ± 0.50 (W) mm x dia 83.00 mm

INTERFACES

Interfaces Wireless LAN IEEE 802.11a/b/g/n/ac (optional), USB 2.0 Type A, USB 2.0 Type B, Ethernet interface (100 Base-TX / 10 Base-T), Drawer kick-out, Powered USB

POWER

Power Supply PS-190
Power Consumption Standby: 1.4 W, Mean: 27.9 W

GENERAL

Product dimensions 145 x 195 x 148 mm (Width x Depth x Height)
Product weight 1.7 kg
Colour Black
Noise Level Standby: 52 dB (A)

FONTS & STYLES

Print Speed 500 mm/sec
Printing Font ANK, Traditional Chinese, Simplified Chinese, Japanese, Korean
Character size 1.41 mm (W) x 3.39 mm (H) / 1.27 mm (W) x 3.39 mm (H)
Character set 95 Alphanumeric, 18 set International, 128 x 43 Graphic, JIS X0208-1990, GB18030-2000, Big5, KSC5601
Dot density 180 DPI x 180 DPI
Printing Characters Text (incl. Euro symbol), Graphics, Barcode, 2D barcode

DATA BUFFER

Data Buffer 4 kB

OTHER

Warranty 48 months Carry in
Optional warranty extension available

LOGISTICS INFORMATION

SKU C31 CJ57132

EAN code 8715946697123

Country of Origin Philippines

Epson TM-T88VII (132): USB, Ethernet, PoweredUSB, Black

WHAT'S IN THE BOX

- Main unit
- Connector Cover
- Paper roll spacer
- Power switch cover
- Roll paper

OPTIONAL ACCESSORIES

- Epson OT-BX88VII (619): Power Supply cover for TM-T88VII, Black
C32C814619
- OT-BZ20-634: Optional External Buzzer
C32C890634
- Epson OT-WL06-323: Wireless LAN dongle 2.4/5GHz WE/CE
C32C891323
- UB-E04: 10/100 BaseT Ethernet I/F Board
C32C881008
- Epson UB-P02II
C32C823891
- UB-S01
C32C823361
- UB-S09
C32C823861
- UB-U02III
C32C824121
- UB-U03II
C32C824131



For more information please contact:

Home users: 0343 90 37766
Business users*: 0871 42 37766
Republic of Ireland: 01 436 7742
Or visit us at <https://www.epson.co.uk/contactus>
* 10p per minute plus network extras.

Web: www.epson.co.uk
www.epson.ie

1. - IDC, POS Printer Market Appraisal Western Europe CY 2020, 2020 shipments, published April 2021

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners. Product information is subject to change without prior notice.