

# L 10



Sample image

**Order symbol :** L 10

**EAN :** 6418074035523

**Including :**



**Product nr :** 3730664

**El. number :**

**Description :** Window for 10 modules

- Finland : 3420136
- Denmark : 8212008070
- Sweden : 2539779

**Remarks :** Clear cover

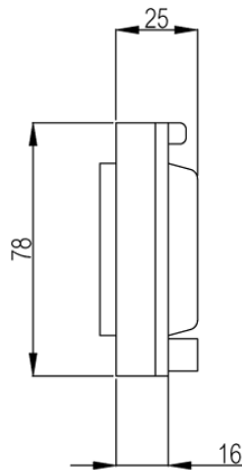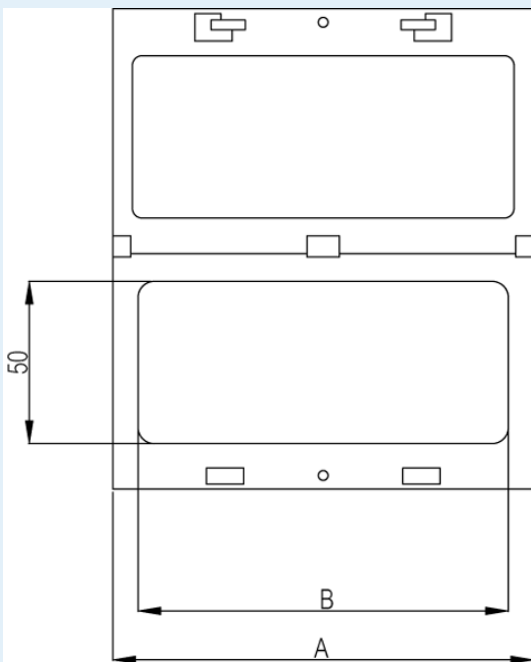

TYPE	A	B
L02	59	44
L04	94.5	78
L06	129.5	114
L08	163	146
L10	200	183

<b>Dimensions :</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	199	77	1
inch :	7.83	3.03	0.04

**Materials :**

Material :  
Base colour :  
Cover colour :  
Gasket material :

**Temperatures :**

Temperature °C (short term) : -40 ... 120 °C  
Temperature °C (continuous) :  
Temperature °F (short term) : -40 ... 250 °F  
Temperature °F (continuous) : -40 ... 175 °F

**Rating :**

Ingress protection (EN 60529):  
Impact Resistance (EN 62262):  
Electrical insulation : Not insulated  
Halogen free (DIN/VDE 0472, Part 815): 0  
UV resistance : -  
Flammability Rating :  
Glow Wire Test (IEC 695-2-1) °C : C  
NEMA Class

**Certificates :**