

# TPCM 090706



Sample image

**Order symbol :** TPCM 090706

**Product nr :** 5824020

**Description :** Enclosure, PC


**Remarks :** Grey cover

**EAN :** 6418074064929

**Including :**

**El. number :**

- Finland :
- Denmark :
- Sweden :

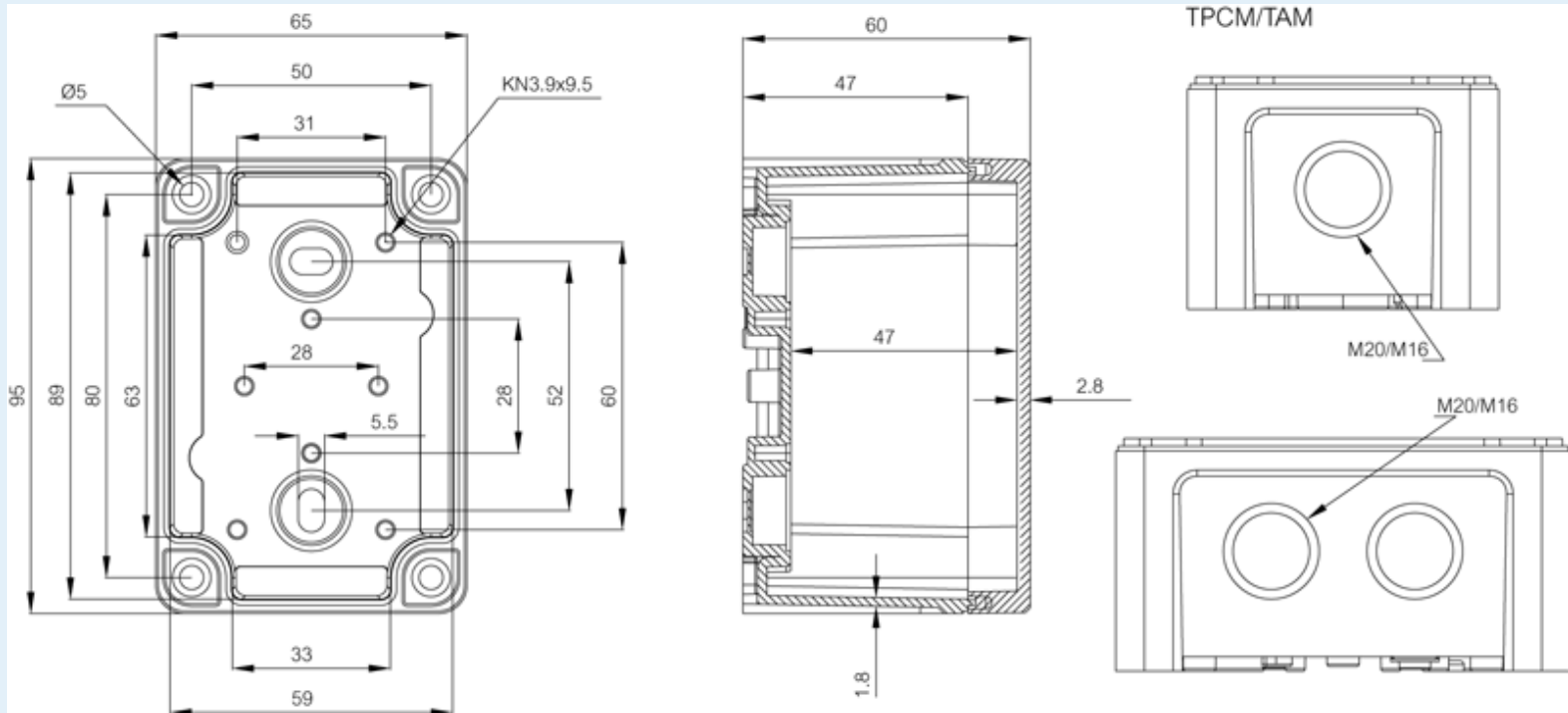

Dimensions :	Height	Width	Depth
mm :	95	65	60
inch :	3.74	2.56	2.36

**Accessories :**

FP 10674 Wall fastening lug (2 pcs) incl. screws

**Materials :**

Material : Polycarbonate  
 Base colour :  
 Cover colour :  
 Gasket material :

**Rating :**

Ingress protection (EN 60529): IP65;  
 Impact Resistance (EN 62262): IK07; IK08;  
 Electrical insulation : Totally insulated  
 Halogen free (DIN/VDE 0472, Part 815): 1  
 UV resistance : -

**Temperatures :**

Temperature °C (short term) : -40 ... 120

Temperature °C (continuous) :

Temperature °F (short term) : -40 ... 250

Temperature °F (continuous) : -40 ... 175

Flammability Rating :

UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C :

960 °C

NEMA Class

**Certificates :**

Certificate FI 40343