

PC 30/25-C3



Sample image

Order symbol : PC 30/25-C3

Product nr : 7520031


Description : Enclosure, PC

Remarks : With aluminium front plate

EAN : 6418074005854

El. number :

- Including :**
- Finland : 3420830
 - Denmark : 8212016596
 - Sweden :

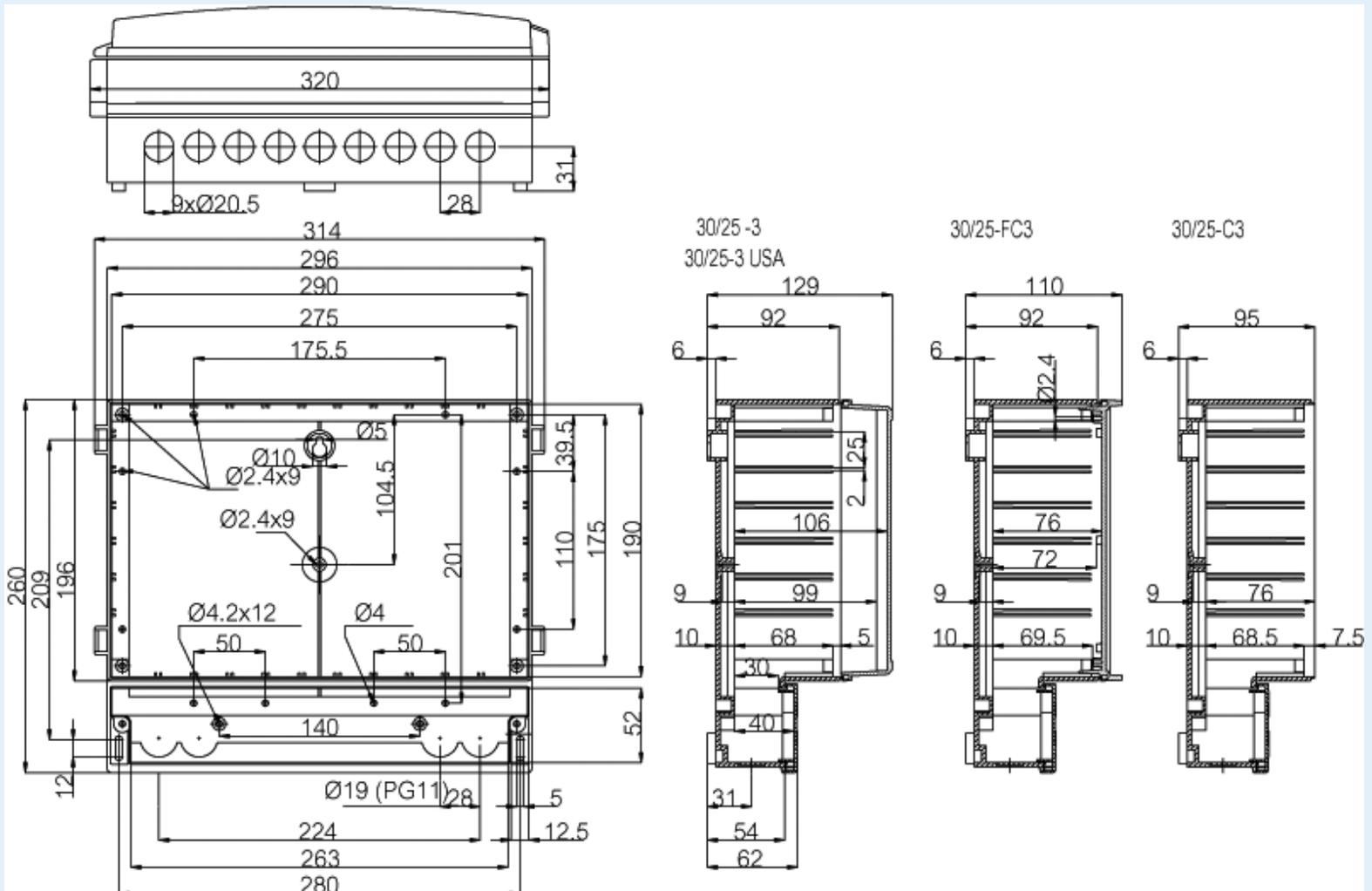

Dimensions :

Height

Width

Depth

Accessories :

mm :	314	260	95
inch :	12.36	10.24	3.74

Materials :

Material :	Polycarbonate
Base colour :	
Cover colour :	
Gasket material :	Polyurethane

Temperatures :

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

FP 30/25	Front plate (aluminium), for enclosures: (290 x 190 x 1)
MP 30/25	Mounting plate, for enclosures: (282 x 215 x 1)
FC PC 30/25	Frame of PC front plate, for enclosures: (296 x 196 x 30)

Rating :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK07;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	

Certificates :

SGSFIMKO_CARDpc