


# MP 36/31

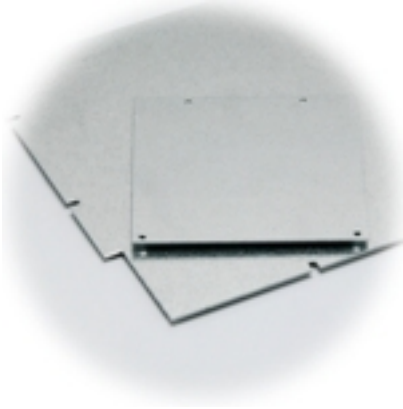

Sample image

**Order symbol :** MP 36/31

**Product nr :** 7720036

**Description :** Mounting plate, for enclosures:


**Remarks :** 383x316x134, 390x316x167

**EAN :** 6418074033406

**El. number :**

- Finland : 3422920
- Denmark : 8212016444
- Sweden : 2535024

**Including :**

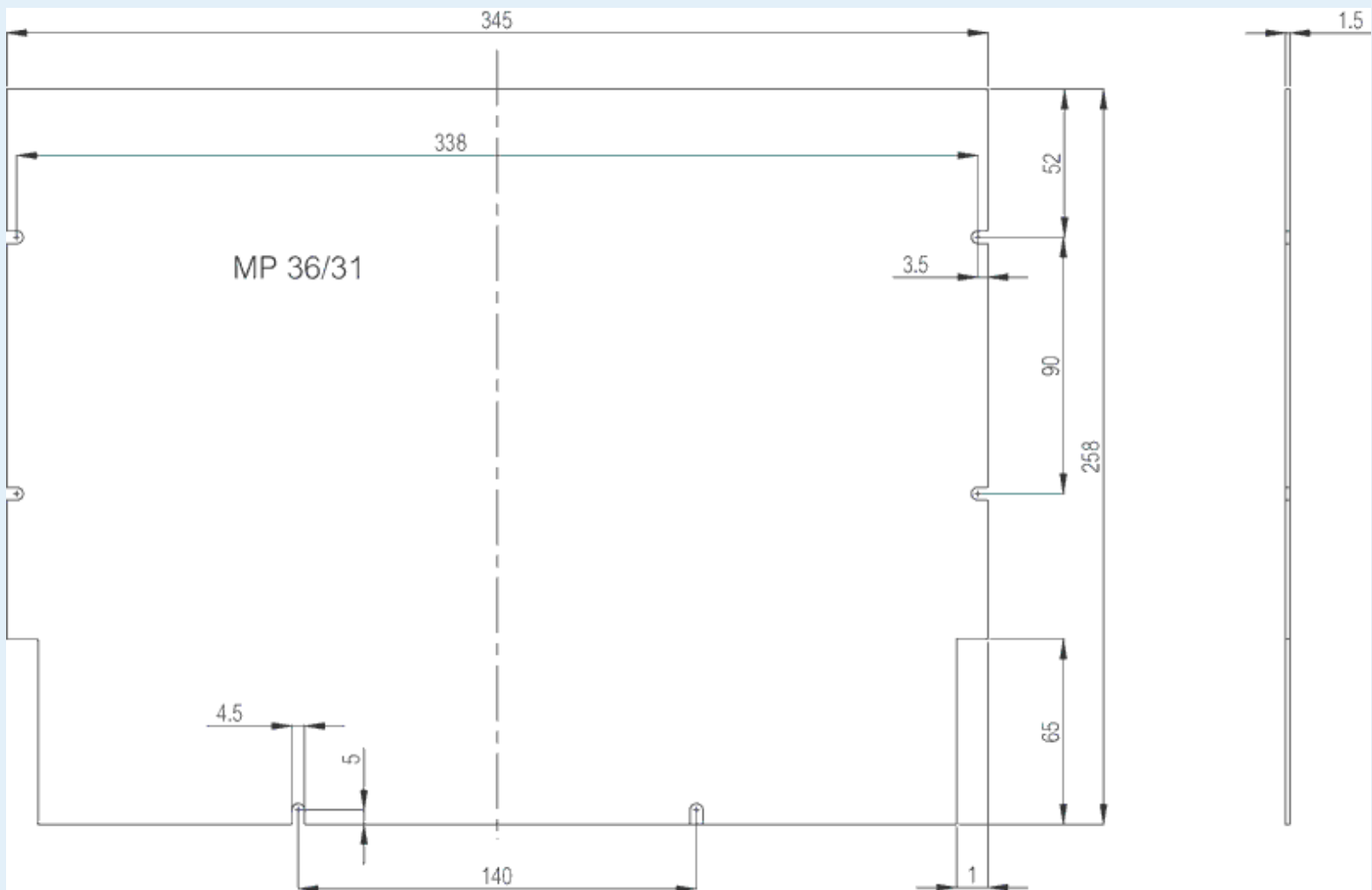

**Dimensions :**

	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	345	258	1
inch :	13.58	10.16	0.04

**Materials :**

Material :  
Base colour :  
Cover colour :  
Gasket material :

**Temperatures :**

Temperature °C (short term) :  
Temperature °C (continuous) :  
Temperature °F (short term) :  
Temperature °F (continuous) :

**Rating :**

Ingress protection (EN 60529):  
Impact Resistance (EN 62262):  
Electrical insulation : Not insulated  
Halogen free (DIN/VDE 0472, Part 815): 0  
UV resistance : -  
Flammability Rating :  
Glow Wire Test (IEC 695-2-1) °C : C  
NEMA Class

**Certificates :**