


# FC PC 21/18

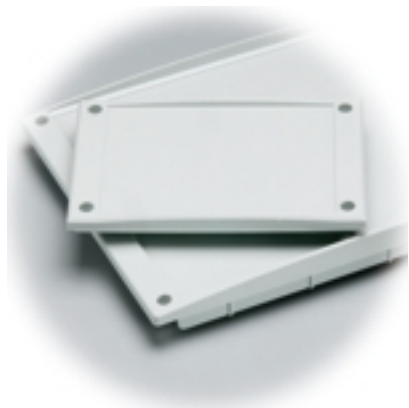

Sample image

**Order symbol :** FC PC 21/18

**Product nr :** 7720100

**Description :** Frame of PC front plate, for enclosures:

**Remarks :** 213x185x90, 213x185x102, 235x185x119

**EAN :** 6418074034670

**Including :**

**El. number :**

- Finland :
- Denmark : 8212016839
- Sweden :

FIBOX\_CM2118-3FC

| <b>Dimensions :</b> | <b>Height</b> | <b>Width</b> | <b>Depth</b> |
|---------------------|---------------|--------------|--------------|
| mm :                | 213           | 125          | 20           |
| inch :              | 8.39          | 4.92         | 0.79         |

**Materials :**

Material :

Base colour :

Cover colour :

Gasket material :

**Rating :**

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation :

Not insulated

Halogen free (DIN/VDE 0472, Part 815):

0

UV resistance :

-

Flammability Rating :

Glow Wire Test (IEC 695-2-1) °C :

C

NEMA Class

**Temperatures :**

Temperature °C (short term) :

Temperature °C (continuous) :

Temperature °F (short term) :

Temperature °F (continuous) :

**Certificates :**