

FC PC 25/22



Sample image

Order symbol : FC PC 25/22

Product nr : 7720111

Description : Frame of PC front plate, for enclosures:


Remarks : 257x219x122, 257x219x135, 280x219x156

Including :

EAN : 6418074059338

El. number :

- Finland :
- Denmark :
- Sweden :

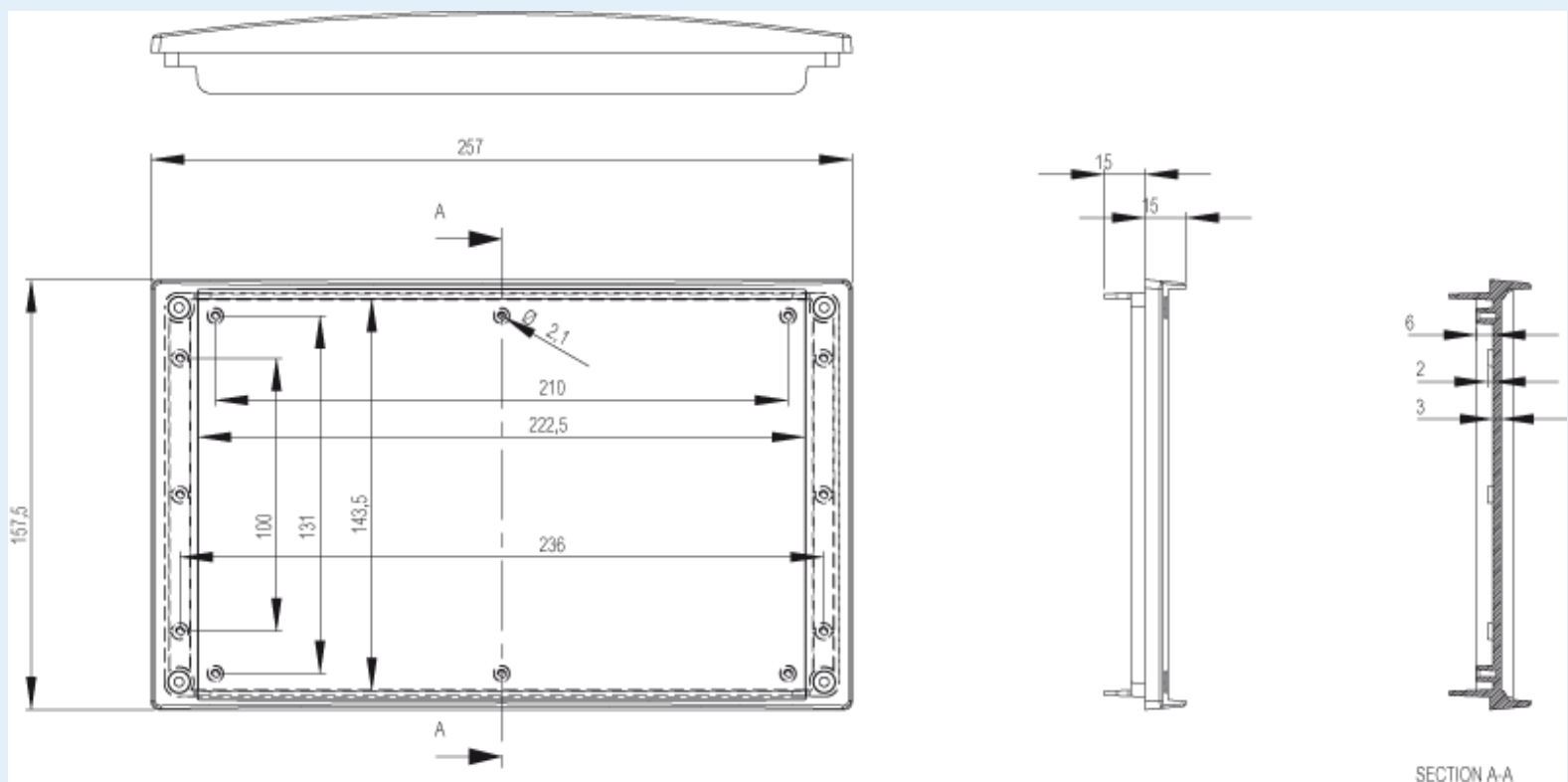

Dimensions :	Height	Width	Depth
mm :	257	157	30
inch :	10.12	6.18	1.18

Materials :

Rating :

Ingress protection (EN 60529):

Impact Resistance (EN 62262):

Electrical insulation :

Halogen free (DIN/VDE 0472, Part 815):

Not insulated

0

Material :

Base colour :

Cover colour :

Gasket material :

UV resistance :

-

Flammability Rating :

Glow Wire Test (IEC 695-2-1) °C :

C

NEMA Class

Temperatures :

Temperature °C (short term) :

Temperature °C (continuous) :

Temperature °F (short term) :

Temperature °F (continuous) :

Certificates :