

ALN 233311



Sample image

Order symbol : ALN 233311

Product nr : 7811380

UL Code : 7811382

UL Name : ALN UL 233311

Description : Enclosure, aluminium


Remarks : Aluminium

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and stainless steel cover screws.

EAN : 6418074016195

El. number :

- Finland : 3420038
- Denmark : 8212045757
- Sweden : 2500923

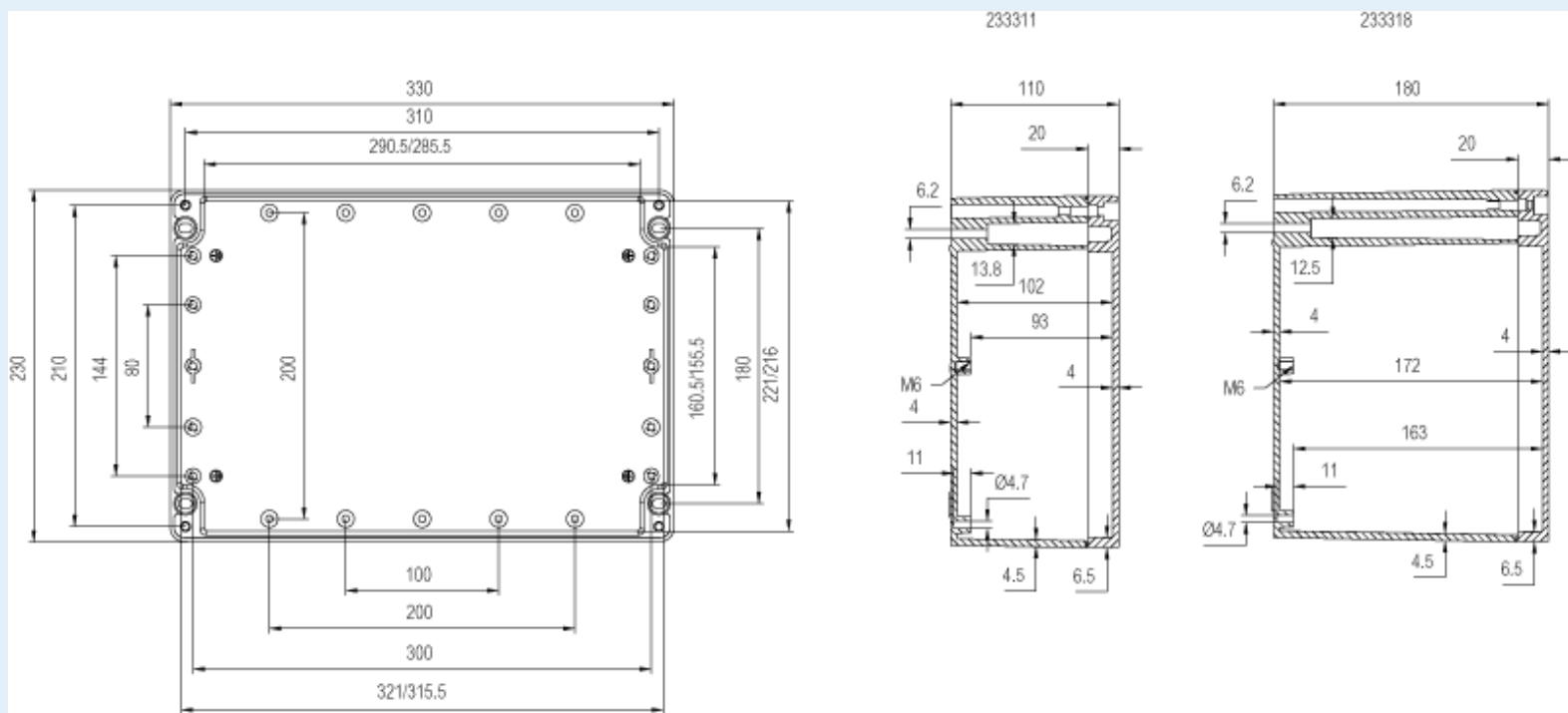

Dimensions :	Height	Width	Depth
mm :	230	330	110
inch :	9.06	12.99	4.33

Rating :	
Ingress protection (EN 60529):	IP66; IP67; IP68;
Impact Resistance (EN 62262):	IK08;

Materials :

Material :	Aluminum
Base colour :	RAL 7001
Cover colour :	RAL 7001
Gasket material :	Polyurethane

Electrical insulation :	Not insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	-
Flammability Rating :	
Glow Wire Test (IEC 695-2-1) °C :	C
NEMA Class	

Temperatures :

Temperature °C (short term) :	-50 ... 120
Temperature °C (continuous) :	-50 ... 80
Temperature °F (short term) :	-60 ... 285
Temperature °F (continuous) :	-60 ... 175

Certificates :

SGSFIMKO_ALU