

CAB PC 203018 T3B

FIBOX
Enclosing innovations



Sample image

Order symbol : CAB PC 203018 T3B

Product nr : 8113036

Description : Cabinet, PC, Smoked transparent door


Remarks : Lock on the short side

EAN : 6418074012548

El. number :

- Finland :
- Denmark : 8212019810
- Sweden :

Including : Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.

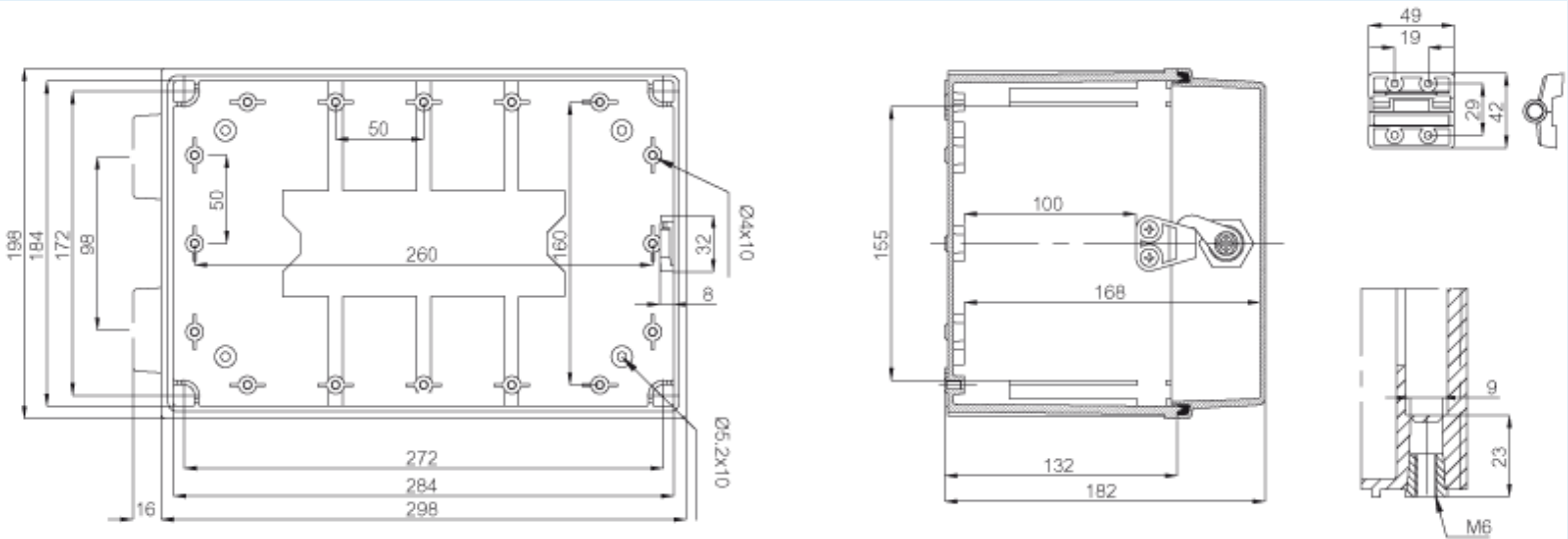

Dimensions :

	Height	Width	Depth
mm :	200	300	180
inch :	7.87	11.81	7.09

Materials :

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey

Accessories :

MB 12225 AL	Swing door set
EKIV 27	DIN-35 Mounting rail, for enclosures: (266 x 35 x 1)
DRF 23	DIN rail frame set, for enclosures:
FP A 23	Swing-out door/Front plate (aluminium), for enclosures: (168 x 268 x 1)
EKIV 17	DIN-35 Mounting rail, for enclosures:

Cover colour : Clear transparent

Gasket material : Polyurethane

(166 x 35 x 1)

EKIV 23 Mounting plate, for enclosures:
(170 x 270 x 1)

Temperatures :

Temperature °C (short term) : -40 ... 120

Temperature °C (continuous) : -40 ... 80

Temperature °F (short term) : -40 ... 250

Temperature °F (continuous) : -40 ... 175

Rating :

Ingress protection (EN 60529): IP65;

Impact Resistance (EN 62262): IK08;

Electrical insulation : Totally insulated

Halogen free (DIN/VDE 0472, Part 815): 1

UV resistance : UL 508

Flammability Rating : UL 746C 5"

Glow Wire Test (IEC 695-2-1) °C : 960 °C

NEMA Class

Certificates :

Certificate FI 40854