

# CAB PC 403018 T3B



Sample image

**Order symbol :** CAB PC 403018 T3B

**Product nr :** 8113052

UL Code : 8143052

UL Name : UL CAB PC 403018 T3B

**Description :** Cabinet, PC, Smoked transparent door



**Remarks :** Locks on the long side

**EAN :** 6418074020253

**El. number :**

- Finland : 3424168
- Denmark : 8212019250
- Sweden : 2539949

**Including :** Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.

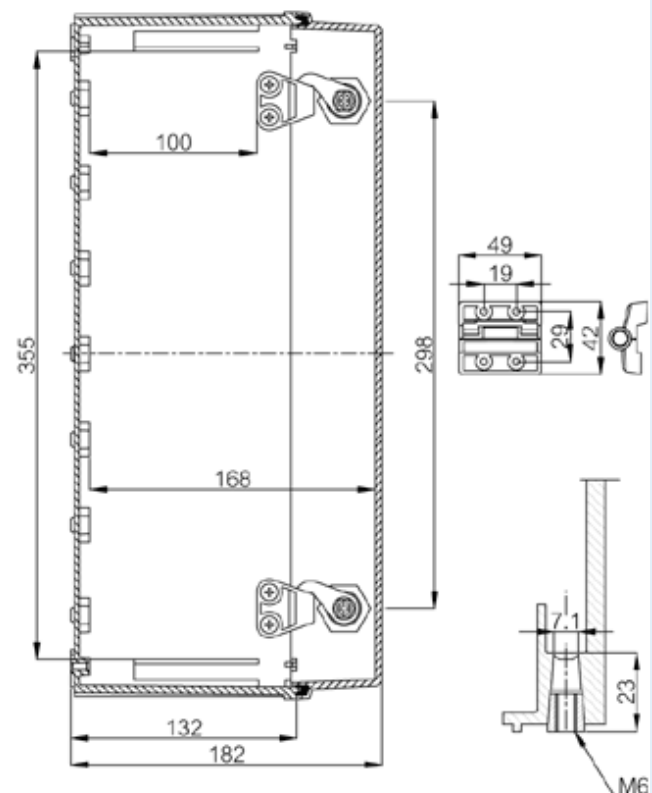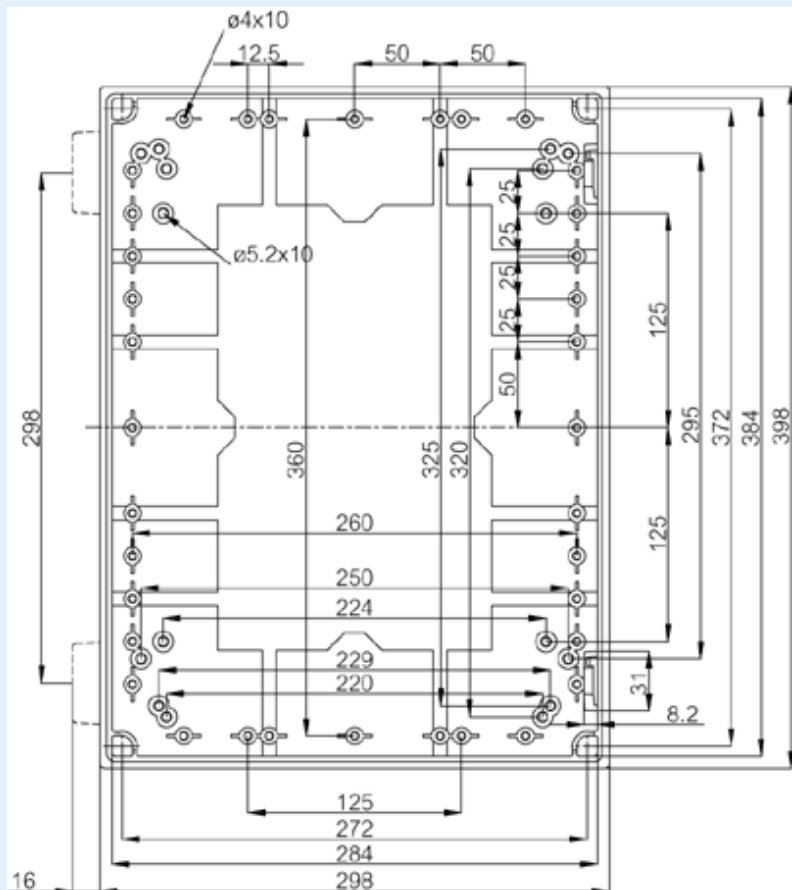

<b>Dimensions :</b>	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	400	300	180
inch :	15.75	11.81	7.09

#### **Materials :**

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	Clear transparent
Gasket material :	Polyurethane

#### **Temperatures :**

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

#### **Accessories :**

DRF 43/44	DIN rail frame set, for enclosures:
MB 12225 AL	Swing door set
EKIV 37	DIN-35 Mounting rail, for enclosures: (366 x 35 x 1)
EKIV 27	DIN-35 Mounting rail, for enclosures: (266 x 35 x 1)
EKIV 43 PL	Mounting plate, plastic, for enclosures: (370 x 270 x 2)
EKIV 43	Mounting plate, for enclosures: (370 x 270 x 1)
FP A 43	Swing-out door/Front plate (aluminium), for enclosures: (268 x 368 x 1)

#### **Rating :**

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	

#### **Certificates :**

Certificate FI 40854