

# CAB PC 302018 G



Sample image

**Order symbol :** CAB PC 302018 G

**Product nr :** 8113330

UL Code : 8143330

UL Name : UL CAB PC 302018 G

**Description :** Cabinet, PC, Grey door


**Remarks :** Latches on the long side

**Including :** Cabinet base. door with PUR gasket. latches. screws for mounting plate/ DIN-rail and corner plugs.

**EAN :** 6418074020000

**El. number :**

- Finland : 3424101
- Denmark : 8212020207
- Sweden : 2539961

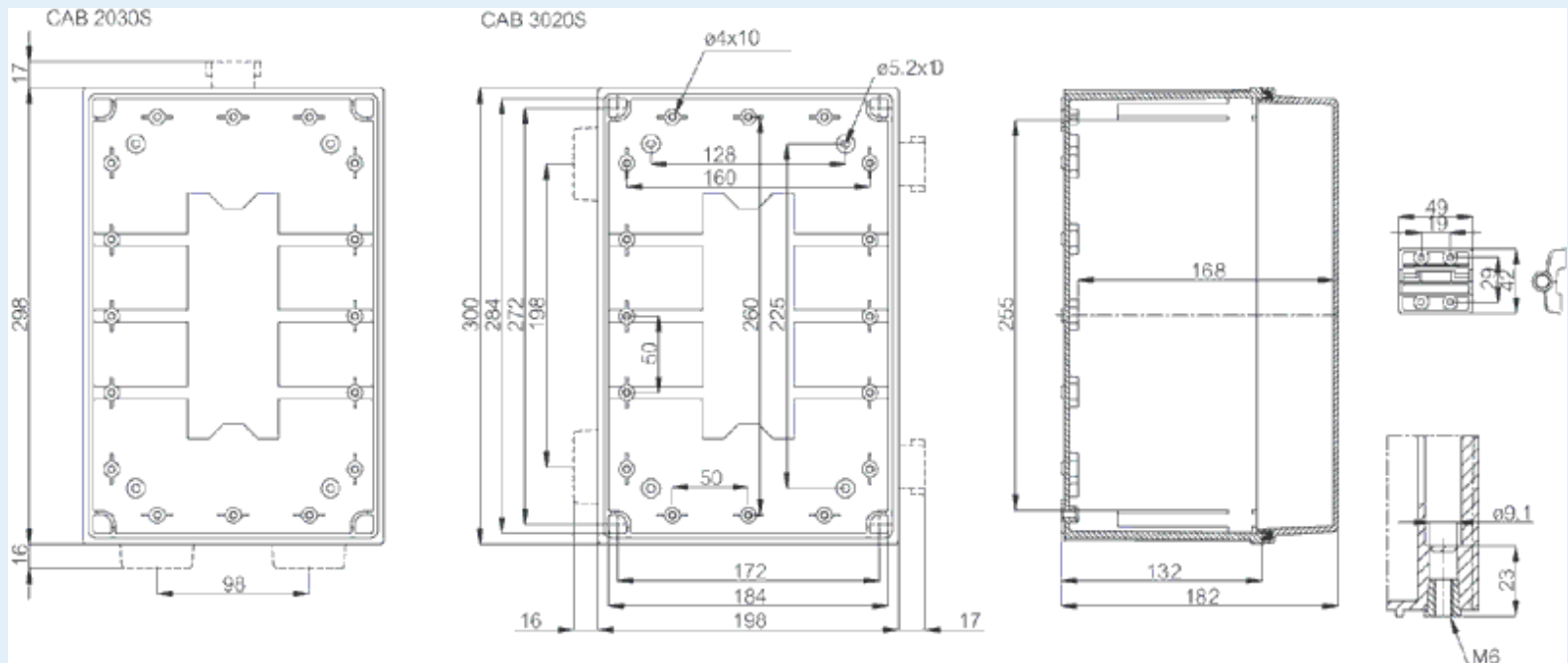

Dimensions :	Height	Width	Depth
mm :	300	200	180
inch :	11.81	7.87	7.09

**Accessories :**

MB 12225	Swing door set
AL	
EKIV 27	DIN-35 Mounting rail, for enclosures: (266 x 35 x 1)
DRF 23	DIN rail frame set, for enclosures:

**Materials :**

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

FP A 23	Swing-out door/Front plate (aluminium), for enclosures: (168 x 268 x 1)
EKIV 17	DIN-35 Mounting rail, for enclosures: (166 x 35 x 1)
EKIV 23	Mounting plate, for enclosures: (170 x 270 x 1)

**Temperatures :**

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

**Rating :**

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	

**Certificates :**

Certificate FI 40854