

ARCA 806030S

FIBOX
Enclosing innovations



Sample image

Order symbol : ARCA 806030S

Product nr : 8120099

Description : Cabinet, PC


Remarks : Grey cover, Swinghandle, hinges on the long side

EAN : 6418074079824

El. number :

- Finland : 3423178
- Denmark : 8212091692
- Sweden :

Including : Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

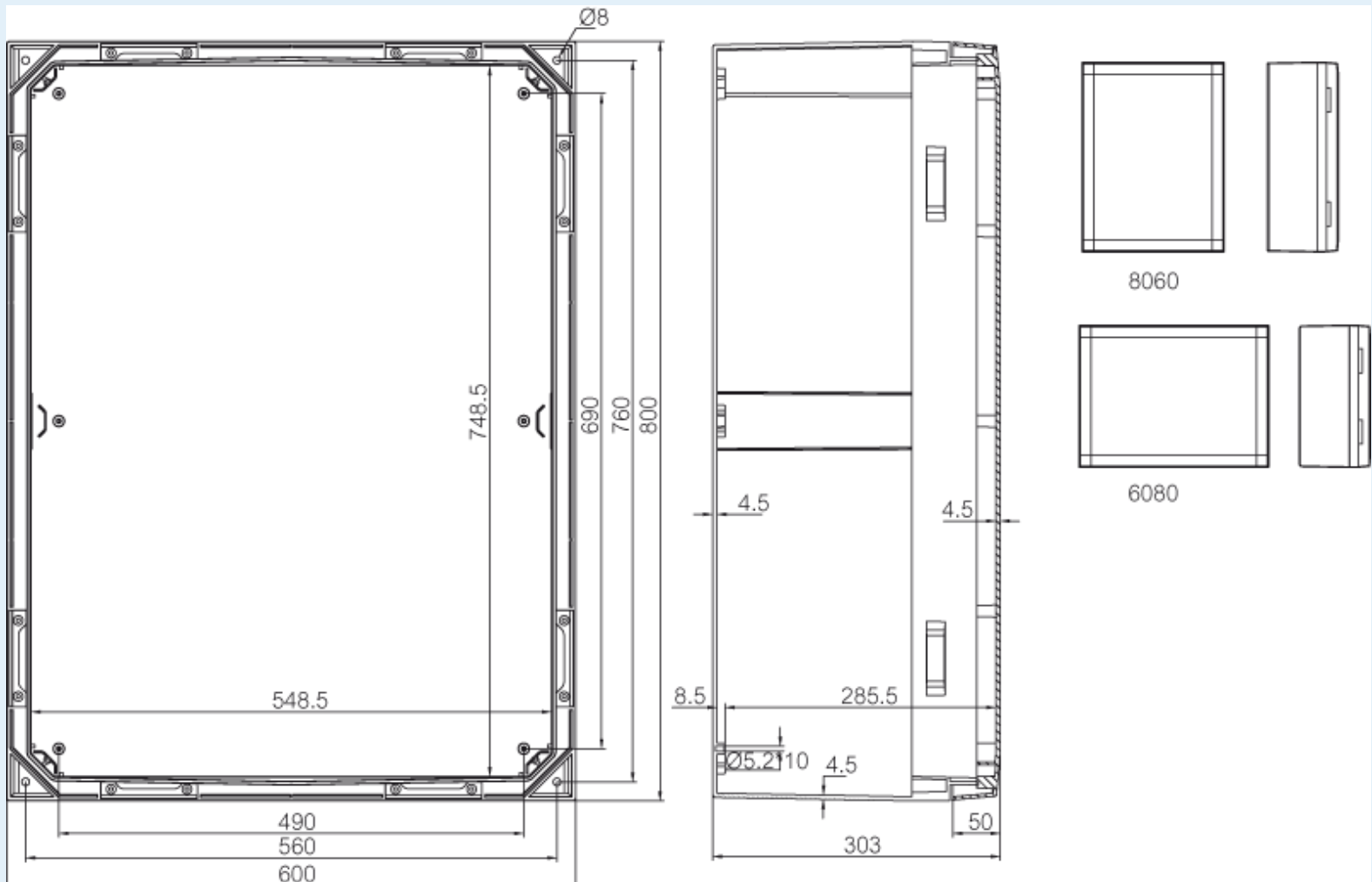

Dimensions :	Height	Width	Depth
mm :	800	600	300
inch :	31.5	23.62	12.2

Materials :

Material :	Polycarbonate
Base colour :	RAL 7035 -light grey
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (short term) :	-40 ... 120
Temperature °C (continuous) :	-40 ... 80
Temperature °F (short term) :	-40 ... 250
Temperature °F (continuous) :	-40 ... 175

Accessories :

RCS ARCA 8060	Rain canopy set for size 8060 (20 x 600 x 30)
PMK ARCA 60	PoleMounting kit, for pole \varnothing 100-300mm (585 x 385 x 35)
IDS ARCA 8060	Inner door set (785 x 585 x 35)
DSP ARCA RM	Door stopper ARCA, right, midsize 5070-8060
DRS ARCA 806030	DIN rail frame set (785 x 585 x 35)
MPS ARCA 8060	Mounting plate (730x530x2 mm) (730 x 530 x 2)
DSP ARCA LM	Door stopper ARCA, left, midsize 5070-8060
MPMP ARCA 8060	Mounting plate multiperforated (730x530x2 mm - \varnothing 3.6 mm) (730 x 530 x 2)
SBK ARCA 80	Support bar kit (715 x 50 x 30)
MPP ARCA 8060	Mounting plate perforated (730x530x2 mm - 26x11 mm) (730 x 530 x 2)
SBK ARCA 60	Support bar kit (535 x 40 x 30)
MPX ARCA 8060	Mounting plate (730x530 mm) (730 x 530 x 5)

Rating :

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance :	UL 508
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960 °C
NEMA Class	

Certificates :

Certificate FI 40467