


# AM 2340

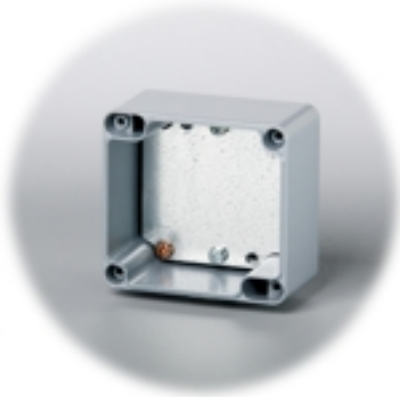

Sample image

**Order symbol :** AM 2340

**Product nr :** 9511018

**Description :** Mounting plate, for enclosures:


**Remarks :** 401x230x110, 401x230x180

**EAN :** 6418074033932

**El. number :**

- Finland : 3423957
- Denmark : 8212005109
- Sweden : 2538784

**Including :**

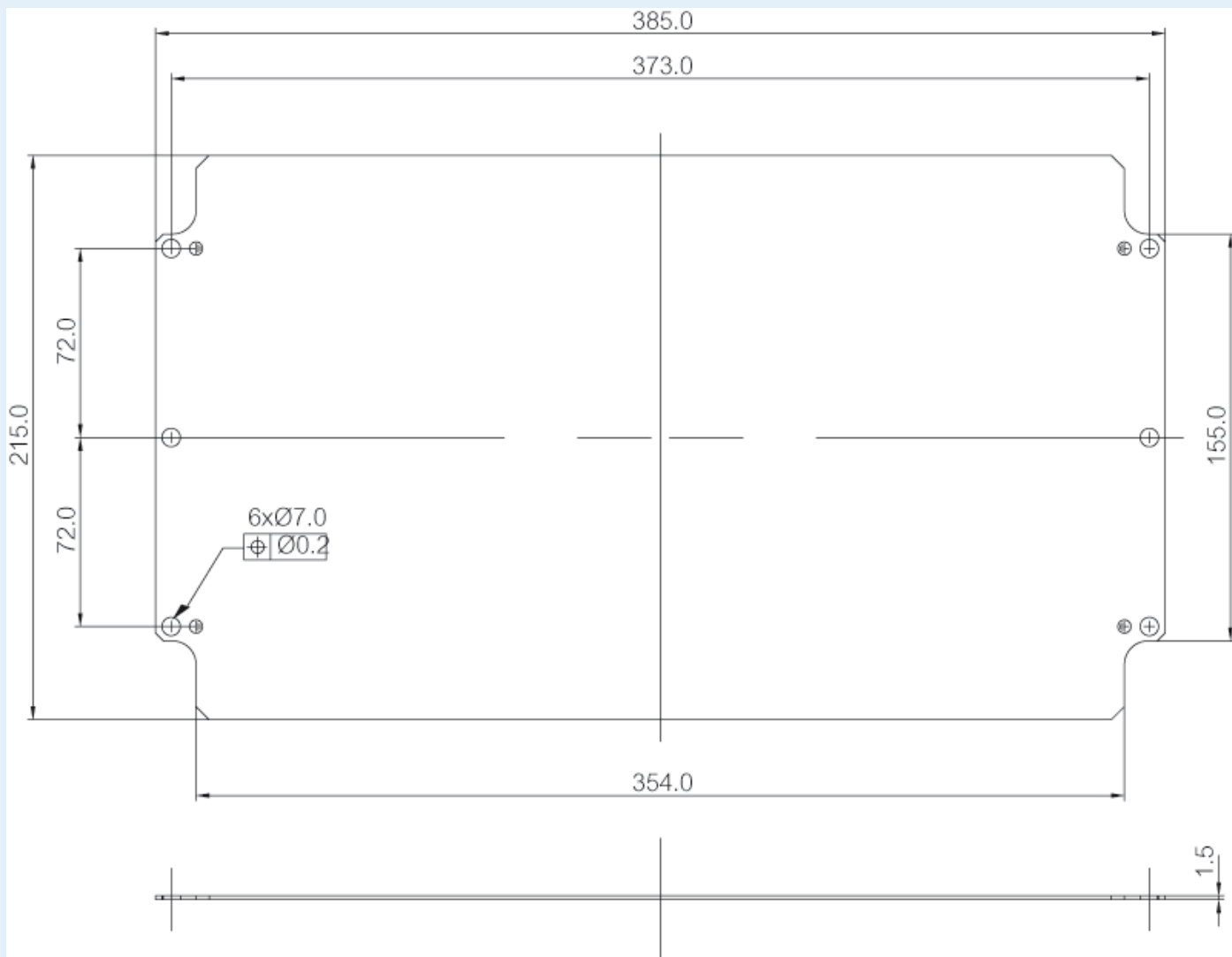

**Dimensions :**

	<b>Height</b>	<b>Width</b>	<b>Depth</b>
mm :	215	385	2
inch :	8.46	15.16	0.08

**Materials :**

Material :  
Base colour :  
Cover colour :  
Gasket material :

**Temperatures :**

Temperature °C (short term) :  
Temperature °C (continuous) :  
Temperature °F (short term) :  
Temperature °F (continuous) :

**Rating :**

Ingress protection (EN 60529):  
Impact Resistance (EN 62262):  
Electrical insulation : Not insulated  
Halogen free (DIN/VDE 0472, Part 815): 0  
UV resistance : -  
Flammability Rating :  
Glow Wire Test (IEC 695-2-1) °C : C  
NEMA Class

**Certificates :**