



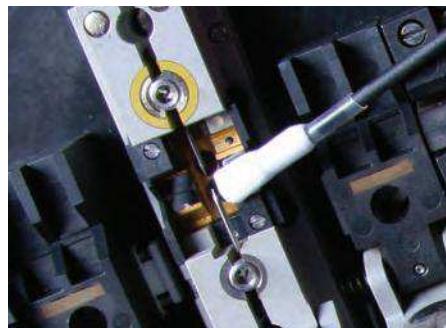

38040

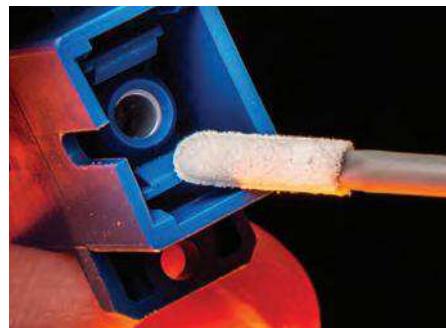

51121



38040

V-Groove & Ferrule Cleaning Swabs

Swab for V-groove and ferrule cleaning

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Thickness	Head Width	Handle Material	Head Material
38540	500/bag	2.7"	0.09"	0.46"	0.04"	0.12"	Polypropylene	Nonwoven
38542F	50/tube	6.9 cm	2.3 mm	11.7 mm	1.0 mm	3.0 mm	Flexible Tip	Polyester



Fusion Splice Mirror Cleaning Swabs

Cleanroom laundered fabric formed into a unique tool for fusion splice mirror cleaning

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Thickness	Head Width	Handle Material	Head Material
51121	25/bag	2.8"/7.1 cm	0.10"/2.5 mm	0.40"/10.2 mm	0.25"/6.5 mm	0.23"/5.7 mm	Glass Filled Nylon	Knit Polyester
51125F	15/tube							



SFF High Density Connector Swab

Swab for cleaning high-density Small Form Factor connections

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Thickness	Head Width	Handle Material	Head Material
38040	500/bag	2.7"/6.9 cm	0.09"/2.3 mm	0.44"/11.2 mm	0.09"/2.4 mm	0.12"/3.0 mm	Polypropylene Flexible Tip	Knit Polyester



SFF Connector Flat Swab

Flat swab provides outstanding particle entrapment



Top View

Side View



38140

Product	Pkg Count	Swab Length	Handle Width	Head Length	Head Thickness	Head Width	Handle Material	Head Material
38140	500/bag	2.7"/6.9 cm	0.09"/2.3 mm	0.48"/12.1 mm	0.06"/1.6 mm	0.12"/3.0 mm	Polypropylene Flexible Tip	Knit Polyester

