

12V Flexiprint

RGB (PLCC6)

Specifications

Voltage	12V
Current	3x1A
Wattage	7.2W/m (3x2.4W/m)
Number of LED's	150pcs
Length of Stripe	5m
Operating Temperature	-25°~+60°C
Storage Temperature	-40°~+80°C
Viewing Angle	110°
CE/RoHS compliant	




Benefits

Adhesive tape on backside
Cuttable every ~100mm

Electrical and Optical Characteristics (Ta=25°C)

Part Number	Colour	Wavelength / CCT	Intensity lm (typ.)	EEC
FP-F01B-500	● red	624nm	120	D
	● green	518nm	230	B
	● blue	471nm	55	E
				Total: E

Dimensions

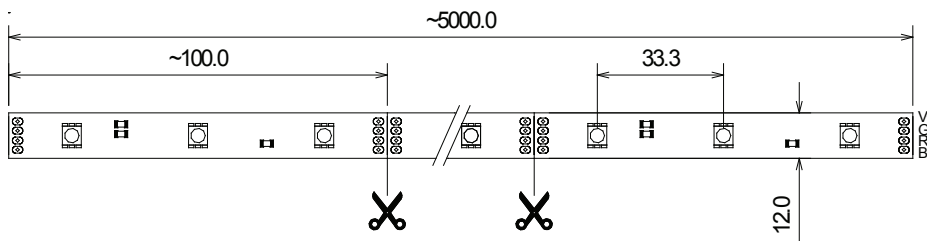

Sloan_03_GK_LED-Modules_I5B

Thickness: 2.1 mm

1. All dimensions are in millimetres
2. Tolerance is ± 0.25 mm unless otherwise specified
3. Specifications are subject to change without notice

Please also take note of our **General Information for Flexiprint and LED Modules**