

SL.161 | 1/2" maintenance free pear head ratchet





Standards:

NF ISO 3315, ISO 3315, DIN 3122, ASME B107.10

Description:

- Dust proof, maintenance free mechanism.
- 72 teeth mechanism for 5° increments.
- Drive direction switch allows easy reversal even with gloved or greasy hands.
- Palm control system - allows the operator to press down on the head avoiding risk of accidental reverse
- Ultra-compact head.
- Hook for hanging when working at height.
- Ergonomic comfort grip handle design resistant to workshop chemicals and solvents.

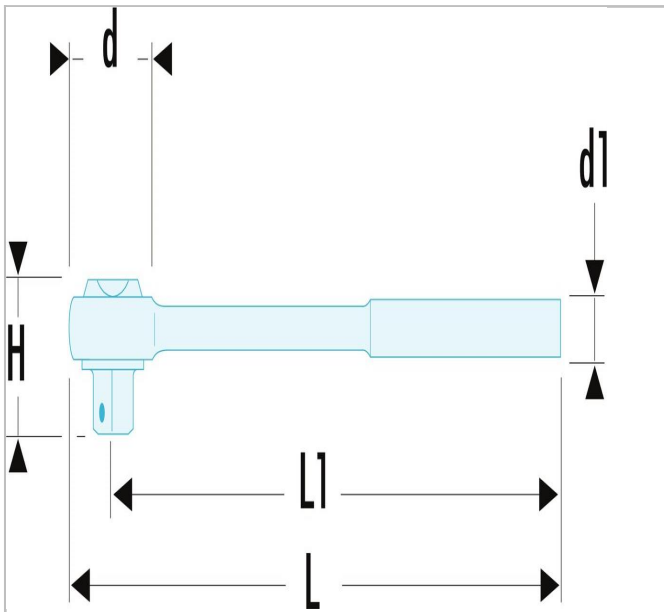

	SL.161
Diameter [mm]	37.0
Diameter D1 [mm]	32.0
Length L [mm]	262.0
Length L1 [mm]	245.0
Height H [mm]	37.0
Weight [g]	445.0