


Axial kit EAMM-A-D40-57A

Part number: 543154

FESTO

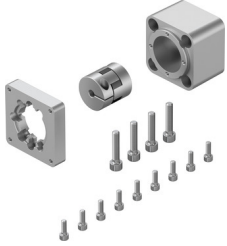

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Transmittable torque	6.5 Nm
Product weight	350 g
Interface code, actuator	D40A D40B D40C
Interface code, motor in	57A
Note on materials	RoHS-compliant