

GP Batteries

PRODUCT SPECIFICATION

Multiuse Work Light Model: C33

Revision History

Revision	Date	Initiator	Reason for Change
1.0	4 th Jan 2019		First Release

Prepared By	Approved By
Wallace Tso	Wallace Tso
Date: 4 th Jan 2019	Date: 4 th Jan 2019


GPI International Limited

7/F, Building 16W, 16 Science Park West Avenue
Hong Kong Science Park, New Territories, Hong Kong,
Tel: (852) 2484 3333 Fax: (852) 24805912
Email: gpii@goldpeak.com
Website: <http://www.gpbatteries.com>

GP Batteries

Product Specifications

Model no.: C33

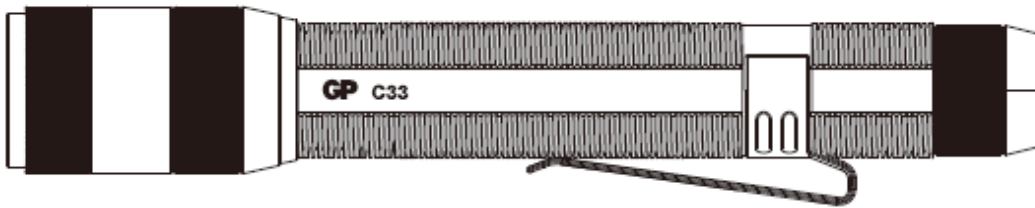

Product Name	: Multiuse Work Light
Lumen output*	: Front LED: 150lm / 30lm (+/- 15%) Side COB: 180lm (+/- 15%)
Beam Distance*	: Max 100m (+/- 15%)
Runtime	: <u>Front LED</u> 150lm: 2.5 hours / 30lm: 20 hours <u>Side COB</u> 180lm: 2 hours
Battery type	: 2 x AA (Alkaline / NiMH)
LED chip	: CREE LED
IP rate*	: IPX4
Shock proof*	: Impact resistant, 1m
Dimensions	: 26 x 163 mm (Include keyring)
Weight	: 82.2 g (without batteries), 128 g (with batteries)
Accessories Included	: 2 x AA Batteries
Certification	: CE, ROHS