


Polyurethane-tyred wheel Ø 75x40 ball bearing

Heavy duty wheel

PRODUCT

Article number **23-040-075B20**

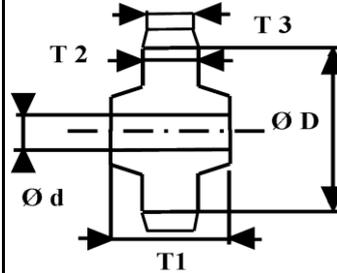

Product Details

Wheel Rim : machined steel.
 Tyre : cast bonded polyurethane.
 Hub : symmetrical, with shielded ball bearings.

TECHNICAL DATA

Specifications

Wheel Diameter - ØD ± 1%	75 mm
Hub Type	2 Ball bearings - 6204 ZZ
Hub Length T1	40 mm ±1
Width of Tread T2	40 mm ±3
Width of Tread-on floor T3	40 mm
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±3	A 93 Shore
Load capacity	300 Kg
Temperature	-25 / +70 °C

Applications :

Pallet trucks and heavy-load materials handling requiring only a small wheel diameter.
 High degree of resistance to abrasion.