

Carrier marking system, laser printer

Helafix HC and HCR Carriers


Marking of cable looms, cables, pipes, transport systems, valves, sensors, for inventory marking on machines or other parts.

Features and benefits

- Versatile transparent carriers for HFX labels used for temporary or permanent marking
- Fixed in place using T18 series cable ties, screws or rivets (carrier HCR06, no rivet hole)
- Protects inserted HFX label against damp, dirt, damage and UV radiation
- Helafix HC supplied as cut lengths in bags, pre-cut and pre-punched rivet hole (carrier HCR06 has no punched hole)
- Helafix HCR supplied in continuous tube format and can be cut to size with HCT tool
- Helafix HFX labels designed to fit into HC and HCR carriers



Multi-purpose identification potential: Helafix HC and HCR.

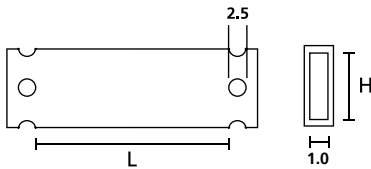

| | |
|----------------------------------|--|
| MATERIAL | Polyethylene, UV Resistant (PEUV) |
| Operating Temperature | -60 °C to +65 °C |
| Flammability | UL 94 HB |
| Chem. Material Properties | Resistance to UV light, water and a variety of solvents. |



| TYPE | Length (L) | Height (H) | Reel Length | Pack Cont. | Recommended Labels | Tools | Article-No. |
|---------|------------|------------|-------------|------------|--------------------|-------|-------------|
| HCR06 | - | 7.0 | 25 m | 25 m | - | - | 525-07003 |
| HCR09 | - | 10.0 | 25 m | 25 m | HFX9 | 50 | 525-10003 |
| HCR12 | - | 13.0 | 25 m | 25 m | HFX12 | 51 | 525-13003 |
| HCR18 | - | 19.0 | 25 m | 25 m | - | - | 525-19003 |
| HCR24 | - | 25.0 | 25 m | 25 m | - | - | 525-25003 |
| HC06-17 | 17.5 | 7.0 | - | 50 pcs. | - | - | 525-07173 |
| HC09-17 | 17.5 | 10.0 | - | 50 pcs. | HFX9-17P | - | 525-10173 |
| HC12-17 | 17.5 | 13.0 | - | 50 pcs. | - | - | 525-13173 |
| HC06-35 | 35.0 | 7.0 | - | 50 pcs. | - | - | 525-07353 |
| HC09-35 | 35.0 | 10.0 | - | 50 pcs. | HFX9-35P | - | 525-10353 |
| HC12-35 | 35.0 | 13.0 | - | 50 pcs. | HFX12-35P | - | 525-13353 |
| HC18-35 | 35.0 | 19.0 | - | 50 pcs. | - | - | 525-19353 |
| HC09-52 | 52.0 | 10.0 | - | 50 pcs. | HFX9-52P | - | 525-10523 |
| HC12-52 | 52.0 | 13.0 | - | 50 pcs. | HFX12-52P | - | 525-13523 |
| HC18-52 | 52.0 | 19.0 | - | 50 pcs. | - | - | 525-19523 |
| HC24-52 | 52.0 | 25.0 | - | 50 pcs. | - | - | 525-25523 |
| HC12-70 | 70.0 | 13.0 | - | 50 pcs. | - | - | 525-13703 |
| HC18-70 | 70.0 | 19.0 | - | 50 pcs. | - | - | 525-19703 |
| HC24-70 | 70.0 | 25.0 | - | 50 pcs. | - | - | 525-25703 |

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

| Recommended Tools | | |
|-------------------|------|------|
| | 50 | 51 |
| | HCT1 | HCT2 |
| | 571 | 571 |

For more information on toolings please refer to the Application Tooling chapter.

