


### Heat Shrinkable Tubing 2:1 flexible and coloured

#### HFT-A - self extinguishing

This high performance thin wall tubing is used extensively for electrical and mechanical protection. It is also well proven for sleeve marking to identify wiring circuits.

#### Features and benefits


- Flexible heat shrink tubing
- Fast shrinking, easy handling, good mechanical strength
- Wide range of colours
- Internal diameters up to 101.6 mm (4 inches)
- UL-224 ,CSA listed and VG approved

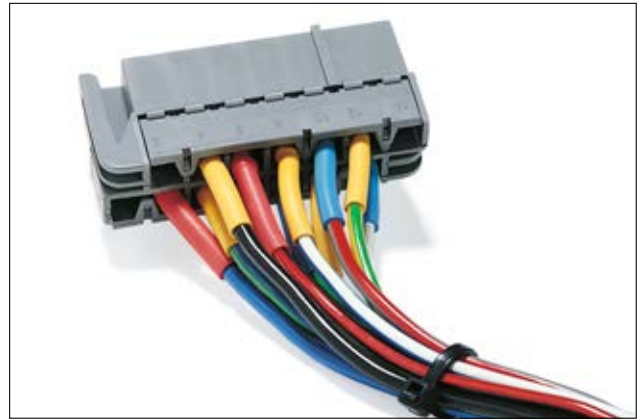

HFT-A conforms to major standards used in all Defence industries.



 Standard sizes available in colours black, red, blue, yellow, white and green-yellow.



<b>MATERIAL</b>	Polyolefin, cross-linked (PO-X)
<b>Shrink Ratio</b>	2:1
<b>Operating Temperature</b>	-55 °C to +135 °C
<b>Min. Shrink Temperature</b>	+135 °C
<b>Longitudinal Change After Shrinkage</b>	-5% max.
<b>Dielectric Strength</b>	>21 kV/mm
<b>Flammability</b>	self-extinguishing, UL 224 VW-1




TYPE	Supplied Ø D min.	Size (imperial)	Recov. Ø d max.	Wall (WT)	Reel Length	Colour	Designation as per VG-Norm	Tools	Article-No.
HFT-A-1.2/0.6	1.2	3/64 "	0.6	0.40	400 m	Black (BK)	VG 95343 T05 A 001 A	30	305-01200
	1.2	3/64 "	0.6	0.40	400 m	Blue (BU)	VG 95343 T05 A 001 G	30	305-01206
	1.2	3/64 "	0.6	0.40	400 m	Red (RD)	VG 95343 T05 A 001 C	30	305-01202
	1.2	3/64 "	0.6	0.40	400 m	White (WH)	VG 95343 T05 A 001 L	30	305-01209
	1.2	3/64 "	0.6	0.40	400 m	Yellow (YE)	VG 95343 T05 A 001 E	30	305-01204
HFT-A-1.6/0.8	1.6	1/16 "	0.8	0.40	400 m	Black (BK)	VG 95343 T05 A 002 A	30	305-01600
	1.6	1/16 "	0.8	0.40	400 m	Blue (BU)	VG 95343 T05 A 002 G	30	305-01606
	1.6	1/16 "	0.8	0.40	400 m	Red (RD)	VG 95343 T05 A 002 C	30	305-01602
	1.6	1/16 "	0.8	0.40	400 m	White (WH)	VG 95343 T05 A 002 L	30	305-01609
	1.6	1/16 "	0.8	0.40	400 m	Yellow (YE)	VG 95343 T05 A 002 E	30	305-01604
HFT-A-2.4/1.2	2.4	3/32 "	1.2	0.50	100 m	Blue (BU)	VG 95343 T05 A 003 G	30	305-02406
	2.4	3/32 "	1.2	0.50	100 m	Red (RD)	VG 95343 T05 A 003 C	30	305-02402
	2.4	3/32 "	1.2	0.50	100 m	White (WH)	VG 95343 T05 A 003 L	30	305-02409
	2.4	3/32 "	1.2	0.50	100 m	Yellow (YE)	VG 95343 T05 A 003 E	30	305-02404
	2.4	3/32 "	1.2	0.50	400 m	Black (BK)	VG 95343 T05 A 003 A	30	305-02400

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.



 
For product specific approvals and specifications please refer to the Appendix.





### Heat Shrinkable Tubing 2:1 flexible and coloured
 
#### HFT-A - self extinguishing



TYPE	Supplied Ø D min.	Size (imperial)	Recov. Ø d max.	Wall (WT)	Reel Length	Colour	Designation as per VG-Norm	Tools	Article-No.
HFT-A-3.2/1.6	3.2	1/8 "	1.6	0.50	100 m	Blue (BU)	VG 95343 T05 A 004 G	30	305-03206
	3.2	1/8 "	1.6	0.50	100 m	Green-Yellow (GNYE)	VG 95343 T05 A 004 N	30	305-03245
	3.2	1/8 "	1.6	0.50	100 m	Red (RD)	VG 95343 T05 A 004 C	30	305-03202
	3.2	1/8 "	1.6	0.50	100 m	White (WH)	VG 95343 T05 A 004 L	30	305-03209
	3.2	1/8 "	1.6	0.50	100 m	Yellow (YE)	VG 95343 T05 A 004 E	30	305-03204
	3.2	1/8 "	1.6	0.50	400 m	Black (BK)	VG 95343 T05 A 004 A	30	305-03200
HFT-A-4.8/2.4	4.8	3/16 "	2.4	0.50	75 m	Blue (BU)	VG 95343 T05 A 005 G	30	305-04806
	4.8	3/16 "	2.4	0.50	75 m	Green-Yellow (GNYE)	VG 95343 T05 A 005 N	30	305-04845
	4.8	3/16 "	2.4	0.50	75 m	Red (RD)	VG 95343 T05 A 005 C	30	305-04802
	4.8	3/16 "	2.4	0.50	75 m	White (WH)	VG 95343 T05 A 005 L	30	305-04809
	4.8	3/16 "	2.4	0.50	75 m	Yellow (YE)	VG 95343 T05 A 005 E	30	305-04804
	4.8	3/16 "	2.4	0.50	300 m	Black (BK)	VG 95343 T05 A 005 A	30	305-04800
HFT-A-6.4/3.2	6.4	1/4 "	3.2	0.60	75 m	Blue (BU)	VG 95343 T05 A 006 G	30	305-06406
	6.4	1/4 "	3.2	0.60	75 m	Green-Yellow (GNYE)	VG 95343 T05 A 006 N	30	305-06445
	6.4	1/4 "	3.2	0.60	75 m	Red (RD)	VG 95343 T05 A 006 C	30	305-06402
	6.4	1/4 "	3.2	0.60	75 m	White (WH)	VG 95343 T05 A 006 L	30	305-06409
	6.4	1/4 "	3.2	0.60	75 m	Yellow (YE)	VG 95343 T05 A 006 E	30	305-06404
	6.4	1/4 "	3.2	0.60	300 m	Black (BK)	VG 95343 T05 A 006 A	30	305-06400
HFT-A-9.5/4.8	9.5	3/8 "	4.8	0.60	50 m	Blue (BU)	VG 95343 T05 A 007 G	30	305-09506
	9.5	3/8 "	4.8	0.60	50 m	Green-Yellow (GNYE)	VG 95343 T05 A 007 N	30	305-09545
	9.5	3/8 "	4.8	0.60	50 m	Red (RD)	VG 95343 T05 A 007 C	30	305-09502
	9.5	3/8 "	4.8	0.60	50 m	White (WH)	VG 95343 T05 A 007 L	30	305-09509
	9.5	3/8 "	4.8	0.60	50 m	Yellow (YE)	VG 95343 T05 A 007 E	30	305-09504
	9.5	3/8 "	4.8	0.60	150 m	Black (BK)	VG 95343 T05 A 007 A	30	305-09500
HFT-A-12.7/6.4	12.7	1/2 "	6.4	0.60	50 m	Blue (BU)	VG 95343 T05 A 008 G	30	305-12706
	12.7	1/2 "	6.4	0.60	50 m	Green-Yellow (GNYE)	VG 95343 T05 A 008 N	30	305-12745
	12.7	1/2 "	6.4	0.60	50 m	Red (RD)	VG 95343 T05 A 008 C	30	305-12702
	12.7	1/2 "	6.4	0.60	50 m	White (WH)	VG 95343 T05 A 008 L	30	305-12709
	12.7	1/2 "	6.4	0.60	50 m	Yellow (YE)	VG 95343 T05 A 008 E	30	305-12704
	12.7	1/2 "	6.4	0.60	100 m	Black (BK)	VG 95343 T05 A 008 A	30	305-12700
HFT-A-19.0/9.5	19.0	3/4 "	9.5	0.80	25 m	Blue (BU)	VG 95343 T05 A 009 G	30	305-19006
	19.0	3/4 "	9.5	0.80	25 m	Green-Yellow (GNYE)	VG 95343 T05 A 009 N	30	305-19045
	19.0	3/4 "	9.5	0.80	25 m	Red (RD)	VG 95343 T05 A 009 C	30	305-19002
	19.0	3/4 "	9.5	0.80	25 m	White (WH)	VG 95343 T05 A 009 L	30	305-19009
	19.0	3/4 "	9.5	0.80	25 m	Yellow (YE)	VG 95343 T05 A 009 E	30	305-19004
	19.0	3/4 "	9.5	0.80	50 m	Black (BK)	VG 95343 T05 A 009 A	30	305-19000

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.

 


For product specific approvals and specifications please refer to the Appendix.




Add items to your watchlist!

[www.HT.click/49-237](http://www.HT.click/49-237)



### Heat Shrinkable Tubing 2:1 flexible and coloured
 
#### HFT-A - self extinguishing



TYPE	Supplied Ø D min.	Size (imperial)	Recov. Ø d max.	Wall (WT)	Reel Length	Colour	Designation as per VG-Norm	Tools	Article-No.
HFT-A-25.4/12.7	25.4	1 "	12.7	0.90	25 m	Blue (BU)	VG 95343 T05 A 010 G	30	305-25406
	25.4	1 "	12.7	0.90	25 m	Green-Yellow (GNYE)	VG 95343 T05 A 010 N	30	305-25445
	25.4	1 "	12.7	0.90	25 m	Red (RD)	VG 95343 T05 A 010 C	30	305-25402
	25.4	1 "	12.7	0.90	25 m	White (WH)	VG 95343 T05 A 010 L	30	305-25409
	25.4	1 "	12.7	0.90	25 m	Yellow (YE)	VG 95343 T05 A 010 E	30	305-25404
	25.4	1 "	12.7	0.90	50 m	Black (BK)	VG 95343 T05 A 010 A	30	305-25400
HFT-A-38.0/19.0	38.0	1-1/2 "	19.0	1.00	50 m	Black (BK)	VG 95343 T05 A 011 A	30	305-38100
	38.0	1-1/2 "	19.0	1.00	50 m	Blue (BU)	VG 95343 T05 A 011 G	30	305-38106
	38.0	1-1/2 "	19.0	1.00	50 m	Green-Yellow (GNYE)	VG 95343 T05 A 011 N	30	305-38145
	38.0	1-1/2 "	19.0	1.00	50 m	Red (RD)	VG 95343 T05 A 011 C	30	305-38102
	38.0	1-1/2 "	19.0	1.00	50 m	White (WH)	VG 95343 T05 A 011 L	30	305-38109
	38.0	1-1/2 "	19.0	1.00	50 m	Yellow (YE)	VG 95343 T05 A 011 E	30	305-38104
HFT-A-50.8/25.4	51.0	2 "	25.4	1.10	35 m	Black (BK)	VG 95343 T05 A 012 A	30	305-50800
	51.0	2 "	25.4	1.10	35 m	Blue (BU)	VG 95343 T05 A 012 G	30	305-50806
	51.0	2 "	25.4	1.10	35 m	Red (RD)	VG 95343 T05 A 012 C	30	305-50802
	51.0	2 "	25.4	1.10	35 m	White (WH)	VG 95343 T05 A 012 L	30	305-50809
	51.0	2 "	25.4	1.10	35 m	Yellow (YE)	VG 95343 T05 A 012 E	30	305-50804
HFT-A-76.0/38.0	76.0	3 "	38.0	1.30	25 m	Black (BK)	VG 95343 T05 A 013 A	30	305-76200
	76.0	3 "	38.0	1.30	25 m	Blue (BU)	VG 95343 T05 A 013 G	30	305-76206
	76.0	3 "	38.0	1.30	25 m	Red (RD)	VG 95343 T05 A 013 C	30	305-76202
	76.0	3 "	38.0	1.30	25 m	White (WH)	VG 95343 T05 A 013 L	30	305-76209
	76.0	3 "	38.0	1.30	25 m	Yellow (YE)	VG 95343 T05 A 013 E	30	305-76204
HFT-A-101.6/50.8	102.0	4 "	51.0	1.40	25 m	Black (BK)	VG 95343 T05 A 014 A	30	305-91600
	102.0	4 "	51.0	1.40	25 m	Blue (BU)	VG 95343 T05 A 014 G	30	305-91606
	102.0	4 "	51.0	1.40	25 m	Red (RD)	VG 95343 T05 A 014 C	30	305-91602
	102.0	4 "	51.0	1.40	25 m	White (WH)	VG 95343 T05 A 014 L	30	305-91609
	102.0	4 "	51.0	1.40	25 m	Yellow (YE)	VG 95343 T05 A 014 E	30	305-91604

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content.

Recommended Tools	
	30 H6100
	566

For more information on toolings please refer to the Application Tooling chapter.



For product specific approvals and specifications please refer to the Appendix.



Add items to your watchlist!

[www.HT.click/49-238](http://www.HT.click/49-238)