




Cable Cover, Material: PA6, UL94V0

Helawrap HWPV0

Helawrap HWPV0 is used to bundle and protect cable and wires, especially if there is vibration and abrasion. HWPV0 has excellent flame-retardant properties and is halogen-free.

Features and benefits

- Ideal solution for bundling, protecting and fixing cables
- Quick and effortless to apply
- Self-extinguishing according to UL94 V0
- Very good abrasion protection
- Special profile enables branching off cable at any point
- Can be removed and reapplied often
- Available in several colours and sizes
- Handy applicator tool included

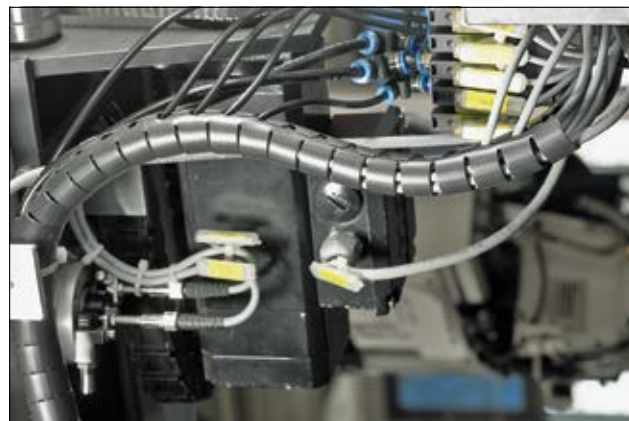

Cables can be branched off at any point for better, more flexible protection.

MATERIAL	Polyamide 6 V0 (PA6V0)
Operating Temperature	-40 °C to +90 °C, intermittent +120 °C
Flammability	UL 94 V0
EN 45545-2 Classification	R22 HL2, R23 HL2

HF ✓

RoHS ✓



To order additional HAT application tools, see page 339.

TYPE	Bundle Ø max.	Colour	Reel Length	Application Tool	Article-No.
HWPV08	9	Black (BK)	25 m	HAT8	161-63101
HWPV016	16	Black (BK)	25 m	HAT16	161-63201
HWPV020	21	Black (BK)	25 m	HAT20	161-63301
HWPV025	27	Black (BK)	25 m	HAT25	161-63401
HWPV030	32	Black (BK)	25 m	HAT30	161-63501

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.

EN 45545-2



For product specific approvals and specifications please refer to the Appendix.

