




## Technical Data

27.11.2023

Electromagnetic protection braided sleeving for hybrid automobiles  
Helagaine HEGEMIP-HY

**HEGEMIP-HY40**

**Article Number 173-04000**

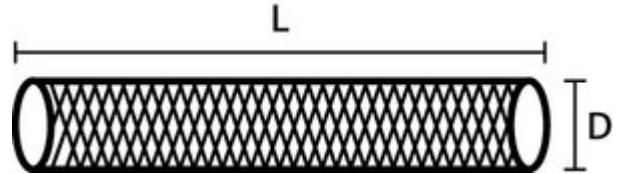

Material:

Polyester (PET), Tin-plated copper (SNCU)

Colour:

Silver (SR), Orange (OG)

Operating Temperature :

-40 °C to +150 °C

Bundle Diameter max (metric):

50 mm

Bundle Ø min.:

30 mm

Weight:

180 g/m

Pack Cont.:

50 m



We assume no responsibility that the Product will be used for the intended purpose, this is beyond our control. It's up to the customer to check the suitability for a specific application by means of tests. Technical changes and errors reserved