



## ICY BOX IB-PS106-PD

### 2-port wall charger with USB Power Delivery

#### Key features

- Compact and energy-efficient Power Delivery 3.0 charger
- Charges compatible devices with USB Power Delivery technology in the shortest possible time
- Power your mobile devices with up to 30 watts via USB Type-C® Power Delivery
- Additional USB Type-A port (QC 3.0) with up to 18 watts
- Universal compatibility with many notebooks, tablets and smartphones
- Intelligent chipset automatically detects the required charging mode
- Safe use through protection against overcharging, overvoltage, overheating and short circuit



#### Packing content

1x IB-PS106-PD, 1x EU adapter, 1x UK adapter, 1x Manual

#### Technical data

<b>Model</b>	IB-PS106-PD
<b>Article no.</b>	60996
<b>EAN code</b>	4250078173311
<b>Colour</b>	Black
<b>Material</b>	ABS
<b>Input</b>	100 - 240 V@50 Hz - 60 Hz
<b>Total output</b>	38 watts
<b>Charge ports</b>	1x USB Type-C®, 1x USB Type-A
<b>Charge standard</b>	PD 3.0 and QC 3.0
<b>Rel. humidity (operating)</b>	10% - 90%
<b>Operating temp. (operating)</b>	0° C - 25° C

<b>Rel. humidity (storage)</b>	5% - 95%
<b>Operating temp. (storage)</b>	-20° C - 80° C
<b>LED</b>	Power
<b>Operating system</b>	Independent
<b>System requirements</b>	USB Type-C® Power Delivery or QC 3.0 enabled computer, tablet or smartphone. Make sure that the voltage and polarity of your devices are compatible with each other! Additional USB charging cables are not included.

Connection	Max. input: AC 100 - 240 V ~50/60 Hz / 1.0 A
<b>USB Type-C® PD 3.0</b>	5 V@3 A = 15 W; 9 V@3 A = 27 W; 12 V@2.5 A = 30 W; 15 V@2 A = 30 W; 20 V@1.5 A = 30 W
<b>USB Type-A QC 3.0</b>	5 V@3 A = 15 W; 9 V@2 A = 18 W; 12 V@1.5 A = 18 W
<b>USB Type-C® + Type-A</b>	20 W + 18 W (Max. 38 W)



USB Type-C® PD 3.0	5 V@3 A	15 W
	9 V@3 A	27 W
	12 V@2.5 A	30 W
	15 V@2 A	30 W
	20 V@1.5 A	30 W


USB Type-A QC 3.0	5 V@3 A	15 W
	9 V@2 A	18 W
	12 V@1.5 A	18 W

## ICY BOX **IB-PS106-PD** 2-port wall charger with USB Power Delivery



### A smart travel companion

The IB-PS106-PD is designed for trips to the EU, UK or overseas in the USA and Canada, because it fits into all existing sockets and charges your mobile devices such as smartphones and tablets. Thanks to the widespread charging standards Power Delivery and QuickCharge, the 2-port charger recharges super fast.

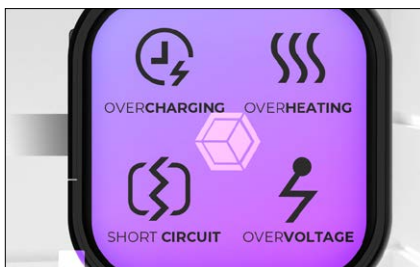

### Safe with ICY BOX

The IB-PS106-PD features an intelligent chipset that always determines the ideal power requirement for the connected mobile devices. The charger guarantees safe operation always and everywhere, which is ensured by protection against overcharging, overvoltage, overheating and short circuit.



### Small and compact

Black, plain, small, compact - an unobtrusive design. But striking in its performance! With up to 38 watts, there is enough power to charge a smartphone and tablet simultaneously. With a USB-A and a USB-C connection, the use of different charging cables is pragmatically solved.

#### Logistical data

<b>Packing unit:</b>	40 pcs. / carton
<b>Total weight:</b>	9.900 kg
<b>Gross weight:</b> (with packing):	0.227 kg
<b>Net weight:</b>	0.081 kg

<b>Dimension/Carton:</b>	450x420x250 mm
<b>Dimension</b> (with packing):	45x100x203 mm
<b>Dimension of article:</b>	31x48x48 mm
<b>Country of Origin:</b>	China