

### Identification ties and plates for marking cable bundles

#### IMP Plates

The IMP and IT range of marker plates are suitable for applying to large cable bundles before or after termination has taken place. The marker plates can also be riveted if required.

They are secured with cable ties of any length with a maximum width of 4.8 mm.

They can be written on by hand using either a black or red T82 indelible marker pen.


#### Features and benefits

- IT and IMP plates for identifying large cable bundles or flat surfaces
- Mark IT and IMP plates with printable labels or T82 pens
- Fix with cable ties or rivets
- Custom printed plaques are available on request



Unlimited cable bundle diameters can be securely identified.

<b>MATERIAL</b>	Polyamide 6.6 (PA66)
<b>Operating Temperature</b>	-40 °C to +85 °C, (+105 °C, 500 h)
<b>Flammability</b>	UL 94 V2

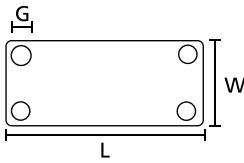

IT1, IMP



Please find the corresponding labels on page 497.

TYPE	Length (L)	Width (W)	Strap Width max. (G)	Pack Cont.	Colour	Recommended Labels	Article-No.
IMP1.5	38.1	19.1	4.8	100 pcs.	White (WH)	TAG18-16TD1	151-42159
IT1	44.0	19.0	4.8	100 pcs.	Natural (NA)	TAG28-16TD1	151-42119
IMP2	50.8	19.3	4.8	100 pcs.	White (WH)	TAG28-16TD1	151-42229
IMP2.5	63.5	19.3	4.8	100 pcs.	White (WH)	TAG43-16TD1	151-42259
IMP2.5W1.75	63.5	44.7	4.8	100 pcs.	White (WH)	TAG43-41TD1	151-42269
IMP3.5	88.9	19.3	4.8	100 pcs.	White (WH)	TAG68-16TD1	151-42359

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

TYPE	Description	Pack Cont.	Colour	Article-No.
T82S-BK	Indelible Marker Pen	2 pcs.	Black (BK)	500-50820
T82R-RD	Indelible Marker Pen	2 pcs.	Red (RD)	500-50822

Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.

