






Description: Autotransformer Input: 230V Output: 80V/100V/125V/150V/170V/190V // 15.0A

Rev.	ST no.	Initials	Sign	Date	Appr.	Sign	Changes
1	59353	AG		13.02.2018	JS		Initial version

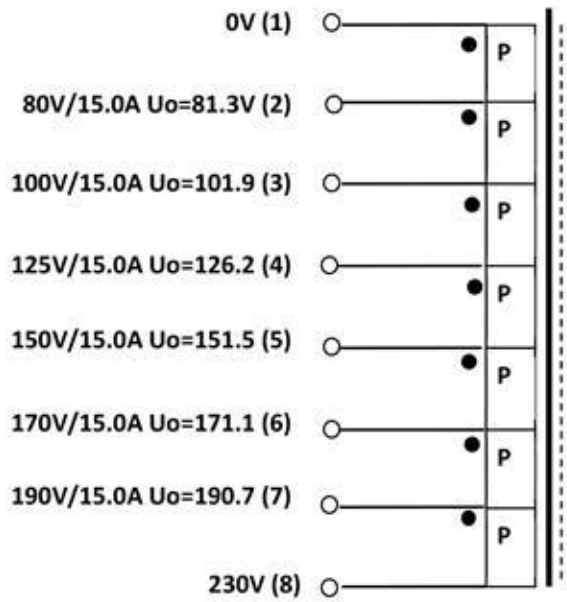

Temperature class: B

T_a = 40°C

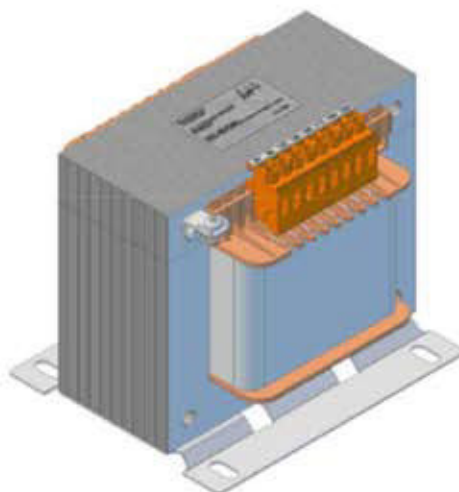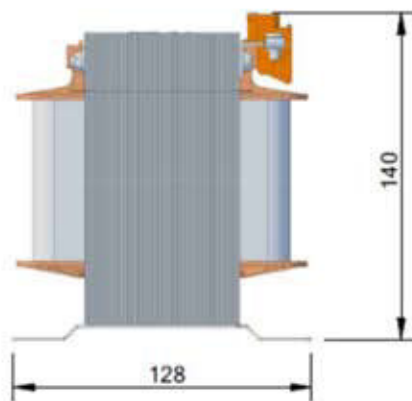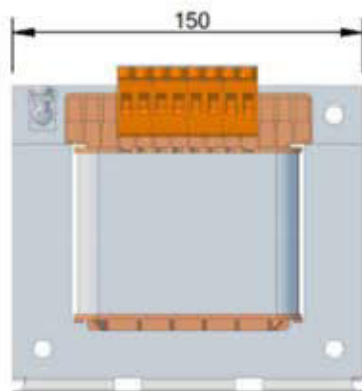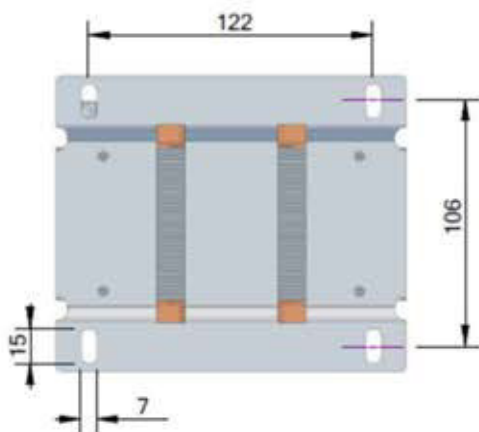

**Scandinavian
Transformer**