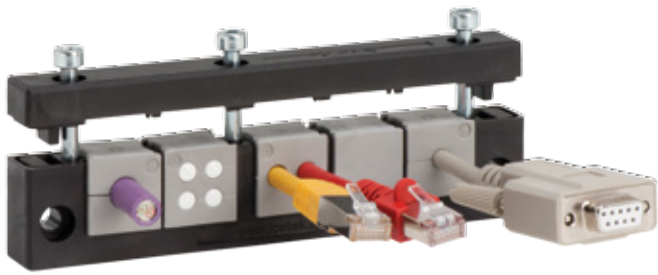


KEL-E

Cable entry frames



KEL-E also available with V2A screws.



KEL-E on request also available with threaded bushings.

1

Product description

The cable entry frames KEL-E are particularly suited for flat connectors. The small frame is ideal for applications with limited space.

For inserting cables up to 17 mm diameter.

Advantages

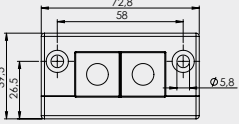
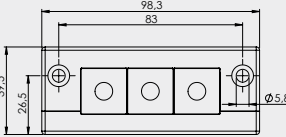
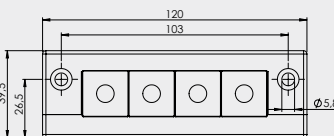
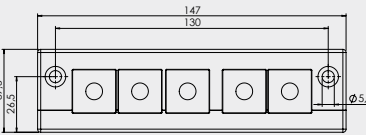
- Warranty of pre-terminated cables remains
- Retrofitting and maintenance can be carried out easily and quickly
- Space saving shape
- Optimal for D-Sub connectors
- Strain relief according EN 50262
- Vibration proof

Specification

Material	Polyamide (PA)
Flame class	UL94-Vo, self-extinguishing
Protection class	IP54, with gasket and correct selection of the cable inserts
Temperature	- 40°C to + 140°C (static)
Properties	Halogen-free, silicone-free
Drilling template	See Page 146 - 147
Height KEL	17 mm

Accessories

KT Cable inserts	Page 28 - 32
KEL-EMC Cable collector	Page 110 - 112

Description	Type	Order No.	Cut-out [mm]	Inserts KT small large	PU
	KEL-E2	42249	43 × 24	2 -	10
	KEL-E2 with V2A screws	42249.200	43 × 24	2 -	10
	KEL-E3	42258	65 × 24	3 -	10
	KEL-E3 with V2A screws	42258.200	65 × 24	3 -	10
	KEL-E4	42259	86 × 24	4 -	10
	KEL-E4 with V2A screws	42259.200	86 × 24	4 -	10
	KEL-E5	42250	112 × 24	5 -	10
	KEL-E5 with V2A screws	42250.200	112 × 24	5 -	10