


plug socket with cable

KMEB-1-230AC-2.5

Part number: 151690

FESTO

Pre-assembled, for MEBH, MOEBH valves and N2 solenoids.

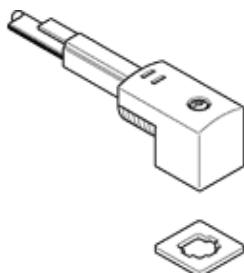

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	125 g
Electrical connection	3-pin Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803
Nominal operating voltage, AC	230 V
Protective earth connection	Available
Cable length	2.5 m
Cable diameter	5.2 mm
Cable structure	3x0,5
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 80 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Corrosion resistance classification CRC	1 - Low corrosion stress
Material cable sheath	PVC
Material housing	PA66-GF30
Material electrical contact	Bronze