

## Brother MFC-J5955DW Inkjet A3 1200 x 4800 DPI 30 ppm Wi-Fi

**Brand :** Brother

**Product code:** MFC-J5955DWRE1


**Product name :** MFC-J5955DW

Brother MFC-J5955DW. Print technology: Inkjet, Printing: Colour printing, Maximum resolution: 1200 x 4800 DPI, Print speed (color, normal quality, A4/US Letter): 30 ppm. Copying: Colour copying, Maximum copy resolution: 600 x 600 DPI. Scanning: Colour scanning, Optical scanning resolution: 1200 x 2400 DPI. Faxing: Colour faxing. Duplex functions: Copy, Fax, Print, Scan. Maximum ISO A-series paper size: A3. Wi-Fi. Direct printing. Product colour: White



<b>Printing</b>		<b>Input &amp; output capacity</b>	
Duplex printing mode	Auto	Auto document feeder capacity	50 sheets
Print technology *	Inkjet	Paper tray media types *	Glossy paper, Plain paper, Recycled paper
Printing *	Colour printing	Maximum ISO A-series paper size *	A3
Duplex printing *	✓	ISO A-series sizes (A0...A9) *	A3,A4,A5,A6
Maximum resolution *	1200 x 4800 DPI	Non-ISO print media sizes	Executive, Folio, Index card, Legal, Letter
Print speed (black, normal quality, A4/US Letter) *	30 ppm	Envelopes sizes	10,C5,Com-10,DL,Monarch
Print speed (color, normal quality, A4/US Letter)	30 ppm	Photo paper sizes	9x13,10x15,13x18,13x20
Duplex print speed (Black, normal quality, A4/US Letter)	21 ppm	Paper tray media weight	64 - 220 g/m <sup>2</sup>
Duplex print speed (color, normal quality, A4/US Letter)	21 ppm	Multi-Purpose Tray media weight	64 - 220 g/m <sup>2</sup>
Time to first page (black, normal)	4.6 s	Ports & interfaces	
<b>Copying</b>		Direct printing *	✓
Duplex copying *	✓	USB port	✓
Copying *	Colour copying	USB 2.0 ports quantity	2
Maximum copy resolution *	600 x 600 DPI	Network	
Maximum copy size	A4	Wi-Fi *	✓
Copy speed (black, normal quality, A4)	25 cpm	Ethernet LAN connection *	✓
Copy speed (colour, normal quality, A4)	16 cpm	Cabling technology	10/100Base-TX)
Copier resize	25 - 400%	Ethernet LAN data rates	10,100 Mbit/s
N-in-1 copy function	✓	Wi-Fi standards	802.11a,802.11b,802.11g,Wi-Fi 4 (802.11n)
PC free copying	✓	Near Field Communication (NFC)	✓
<b>Scanning</b>		Security algorithms	64-bit WEP,128-bit WEP,802.1x RADIUS,EAP-FAST,EAP-PEAP,EAP-TLS,EAP-TTLS,IPSec,SSL/TLS,WPA-AES,WPA-PSK,WPA-TKIP,WPA2-AES,WPA2-PSK,WPA2-TKIP,WPA3-SAE
Duplex scanning *	✓	Mobile printing technologies	Apple AirPrint,Brother iPrint & Scan,Mopria Print Service
Duplex scanning mode	Auto	Performance	
Scanning *	Colour scanning	Internal memory *	512 MB
Optical scanning resolution *	1200 x 2400 DPI	Design	
Scanner type *	Flatbed & ADF scanner	Product colour *	White
Scan technology	CIS	Market positioning *	Home & office
		Built-in display *	✓
		Display diagonal	8.89 cm (3.5")
		Control type	Buttons, Touch
		Colour display	✓

<b>Fax</b>		<b>Energy Management</b>	
Duplex faxing	✓	Power consumption (average operating)	36 W
Faxing *	Colour faxing	Power consumption (ready)	6 W
Modem speed	33.6 Kbit/s	Power consumption (standby)	0.9 W
<b>Features</b>		Energy Star Typical Electricity Consumption (TEC)	
Maximum duty cycle *	3500 pages per month	0.17 kWh/week	
Duplex functions *	Copy, Fax, Print, Scan	<b>Operational Conditions</b>	
Number of print cartridges *	4	Operating relative humidity range	20 - 80%
Printing colors *	Black, Cyan, Magenta, Yellow	Operating temperature range (T-T)	10 - 35 °C
Page description languages	BR-Script 3,PCL 6,PDF 1.7,XPS	<b>Weight &amp; Dimensions</b>	
Printer fonts	PCL	Width	545 mm
<b>Input &amp; output capacity</b>		Depth	436 mm
Total number of input trays *	2	Height	375 mm
Total input capacity *	500 sheets	Weight	20.9 kg
Total output capacity *	100 sheets	<b>Packaging Data</b>	
Paper tray 1 input capacity	250 sheets	Package width	651 mm
Paper tray 2 input capacity	250 sheets	Package depth	518 mm
Multi-Purpose tray	✓	Package height	489 mm
Multi-Purpose tray input capacity	100 sheets	Package weight	23.6 kg
Auto document feeder (ADF)	✓		

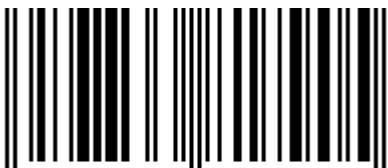

4 977766 817905

Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.