


## Data Sheet | Item Number: 2092-3601/002-000

Gripping plate with sliding connector release; for female and male connectors; 2 parts; Pin spacing 7.5 mm; 3-pole; light gray

<https://www.wago.com/2092-3601/002-000>

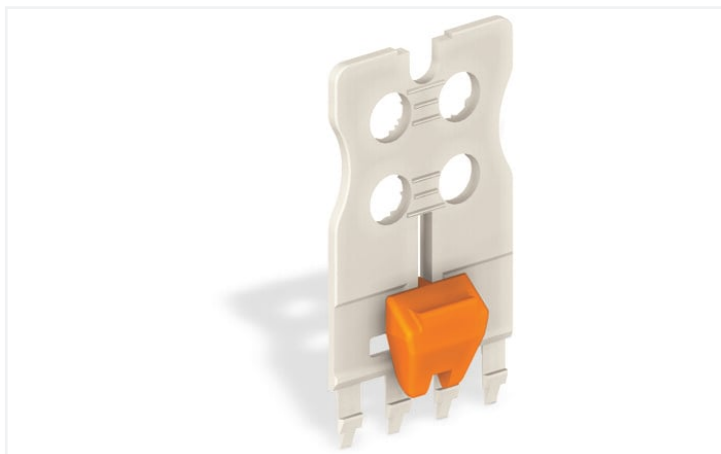

Color: ■ light gray

Similar to illustration

### Physical data

Pin spacing	7.5 mm / 0.295 inches
-------------	-----------------------

### Material data

Note (material data)

[Information on material specifications can be found here](https://www.wago.com/us/material-specifications)

Color	light gray
Material group	I
Insulation material	Polyphthalamide (PPA GF)
Flammability class per UL94	V0
Fire load	0.012 MJ
Weight	0.3 g

### Commercial data

eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 8.0	EC002848
ETIM 7.0	EC002848
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821474203
Customs tariff number	85389099990

**Environmental Product Compliance**

RoHS Compliance Status Compliant, No Exemption

**Approvals / Certificates**

**General approvals**



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2 No. 158	2362521

**Downloads**

**Environmental Product Compliance**


Compliance Search
Environmental Product Compliance 2092-3601/002-000 <span style="float: right;">↓</span>

**Documentation**

Additional Information			
Technical Section	03.04.2019	pdf 2010.85 KB	↓

**Installation Notes**

**Strain relief**

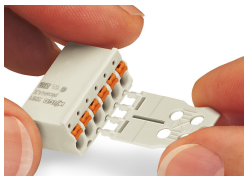

Gripping plates are suitable for factory and field assembly.