

Microsoft Phone MP52

A cost-effective basic Teams phone with high performance, Android 9.0 OS-based Yealink MP52 is plentiful in practical functions and outstanding in calling experience. The design of a non-touchscreen with physical navigation buttons makes the phone suitable for the common area and best migration practice from skype for business to Teams. Powered by Microsoft, MP52 deliver a consistent Teams calling and meeting experience and improve the productivity in daily work.



HAC



Microsoft 365



Android 9.0



Color Screen



HD Audio



Common Area Phone



Key Features and Benefits

Excellent Calling Experience

The Yealink MP52 leverage the advantage of Yealink Optima HD voice and Noise Proof Technology. The full-duplex hands-free speakerphone with AEC & HAC handset makes the phone own a high performance with crystal-clear sounds, also keeps the process of each calling stably and smoothly.

Common Area Phone

That adopt to using in the common area, such as school/hospital/business scenarios, the Yealink MP52 is invulnerable to damage caused by the design of non-touchscreen and physical buttons. Moreover, the appearance of a reasonable panel structure and fewer buttons would be appropriate for deploying the phone in the common area. Users can connect Wi-Fi/Bluetooth dongle and compatible USB headset through the USB type-A port.

Efficient Management

Effectively, MP52 offers an auto-provisioning mechanism with phone development and configuration. Managers also are able to deploy, manage and update the MP52 phone in a variety of flexible ways, which include Microsoft TAC, Yealink, and Unify Square device management platforms.

- Android 9.0
- 2.4 inch (320 x 240) Non-touch Color Screen
- Optimal HD audio, Yealink Noise Proof Technology
- Magnet Handset
- Bluetooth Headset via Dongle BT41
- Wi-Fi via Dongle WF50
- USB Type A port, Supports USB Headset
- Microsoft Teams-tailored APP
- Dual-port 10/100M Ethernet Switch, Supports PoE
- Supports Microsoft/Yealink/Unify Square Device Management Platform
- Wall mountable

Audio Features

- HD voice: HD handset, HD speaker
- Hearing aid compatible (HAC) handset, magnet handset
- Yealink Noise Proof Technology
- Audio codec: SILK, Opus, G.722, G.722.1, G.722.1C, G.711 (A/μ), G.723, G.726, G.729AB, iLBC
- Full-duplex hands-free speakerphone with AEC
- VAD, CNG, AEC, PLC, AJB, AGC

Phone Features

- Incoming/Outgoing P2P call
- Cloud PSTN call
- Call controls
 - Call hold/Call mute/Call transfer/Call forward
 - Visual voicemail
 - Synchronized call logs
- Exchange calendar integration
- Meeting call controls
 - Mute/unmute, hold/resume
 - Hang up
 - Add/remove participant
- Sign in with user credentials
- Sign in via website
- Phone lock/unlock
- Emergency calls
- Hot desking
- Accessibility
- Power saving
- Common Area Phone (CAP)

Display and Indicator

- Color screen with backlight:
 - 2.4 inch (320 x 240) non-touch Screen
- Dark theme
- Multi-language user interface
- Power LED for call and message waiting indication
- Presence status control: available, busy, DND, be

right back, off work, appear away

- Voice Mail button
- Time display

Interface

- Dual-port Gigabit Ethernet, Supports PoE
- Power over Ethernet (IEEE 802.3af), class 3
- 1 x USB Type A port
- 1 x Security lock port
- 1 x RJ9 (4P4C) handset port
- 1 x RJ9 (4P4C) headset port

Management

- Configuration: Browser/Phone/Auto Provisioning and Device Management Platform
- Provisioning priority management
- Auto Provisioning via Activation Code
- Yealink Redirection and Provisioning Service (RPS)
- QoE (Monitoring Reports)
- Reset to factory, reboot
- Package tracing export, system log
- Screenshot via URL
- Supports Microsoft Device Management Platform
- Supports Yealink Device Management Platform (YMDP/YMCS)
- Supports Unify Square Device Management Platform
- Simple Certificate Enrollment Protocol (SCEP)

Network and Security

- IPv4/IPv6
- IP Assignment: Static/DHCP
- Proxy mode
- HTTP/HTTPS web server
- Time and date synchronization using SNTP
- Transport Layer Security (TLS)
- HTTPS certificate manager
- IEEE802.1X

- AES encryption for configuration file


Other Physical Features

- Color: Classic Grey
- External Yealink AC adapter (optional): AC 100~240V input and DC 5V/2A output
- USB output currency: 5V \equiv 500mA
- Power consumption (PSU): 1.5w~4.5w
- Power consumption (PoE): 2.3W~6.0W
- Dimension (W*D*H*T): 212mm*186mm*146mm*42mm
- Operating humidity: 10~95%
- Operating temperature: -10~50°C (+14~122°F)

Package Features

- Package content:
 - Yealink MP52 IP phone
 - Handset with handset cord
 - Ethernet Cable (2m CAT5E FTP Cable)
 - Stand
 - Quick Start Guide
 - Power Adapter (Optional)
- Qty/CTN: 10 PCS
- N.W/CTN: 10.7kg
- G.W/CTN: 11.6kg
- Giftbox size: 238mm* 210mm* 103mm
- Carton Meas: 535mm* 443mm* 250mm

Compliance

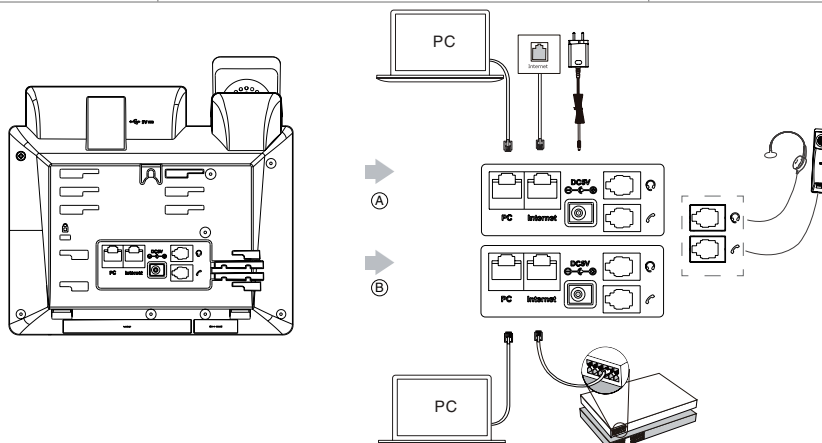

About Yealink

Yealink (Stock Code: 300628) is a global brand that specializes in video conferencing, voice communications and collaboration solutions with best-in-class quality, innovative technology and user-friendly experience. As one of the best providers in more than 140 countries and regions, Yealink ranks No.1 in the global market share of SIP phone shipments (Global IP Desktop Phone Growth Excellence Leadership Award Report, Frost & Sullivan, 2019).

Copyright

Copyright © 2021 YEALINK(XIAMEN) NETWORK TECHNOLOGY CO., LTD.

All rights reserved. No parts of this publication may be reproduced or transmitted in any form or by any means, electronic or mechanical, photocopying, recording, or otherwise, for any purpose, without the express written permission of Yealink(Xiamen) Network Technology CO., LTD.

Technical Support

Visit Yealink WIKI (<http://support.yealink.com/>) for firmware downloads, product documents, FAQ, and more. For better service, we sincerely recommend you to use Yealink Ticketing system (<https://ticket.yealink.com>) to submit all your technical issues.



YEALINK(XIAMEN) NETWORK TECHNOLOGY CO.,LTD.
Web: www.yealink.com
Addr: No.1 Ling-Xia North Road, High Tech Park,
Huli District, Xiamen, Fujian, P.R.C
Copyright©2021 Yealink Inc. All right reserved.