


plug socket MSSD-EB

Part number: 151687

★ Core product range

For solenoid coils and valves, port pattern per DIN EN 175 301, type C.

FESTO

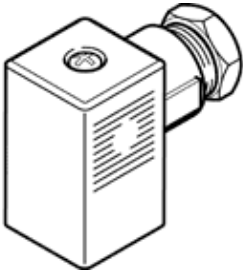

Data sheet

Feature	Value
Mounting type	On solenoid valve with M2.5 central screw
Assembly position	Any
Product weight	11 g
Electrical connection	3-pin Plug socket Plug socket angled Plug pattern type C to EN 175301-803 Per DIN EN 175301-803 According to DIN EN 61984 Rectangular design, MSEB Rectangular design, MSN2
Nominal operating voltage DC	300 V
Nominal operating voltage, AC	250 V
Permissible current load	6 A
Surge strength	4 kV
Cable gland connection	Pg7
Cable diameter	6 ... 8 mm
Permissible cable diameter	7.5 mm
Nominal conductor cross-section	$\leq 0.75 \text{ mm}^2$
Terminal cross-section	0.75 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-45 ... 90 °C
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Degree of contamination	3
Material housing	Plastic
Housing colour	Black
Material seals	NBR