


Micro-Fit TPA Cable Assemblies




Standard Micro-Fit TPA Cable Assemblies deliver an off-the-shelf solution with a variety of cable lengths and a 3.00mm-pitch connector with a 5.0A maximum current rating to facilitate both prototyping and global production

Features and Advantages

Multi-color cable configurations with Micro-Fit TPA Receptacles available off the shelf
Designed to support development and production programs. Multi-color cables ensure correct connection

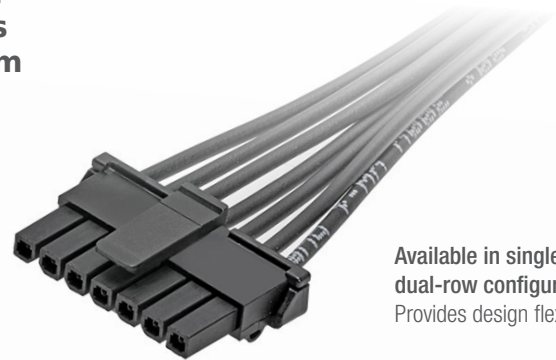

Available in single- and dual-row configurations
Provides design flexibility

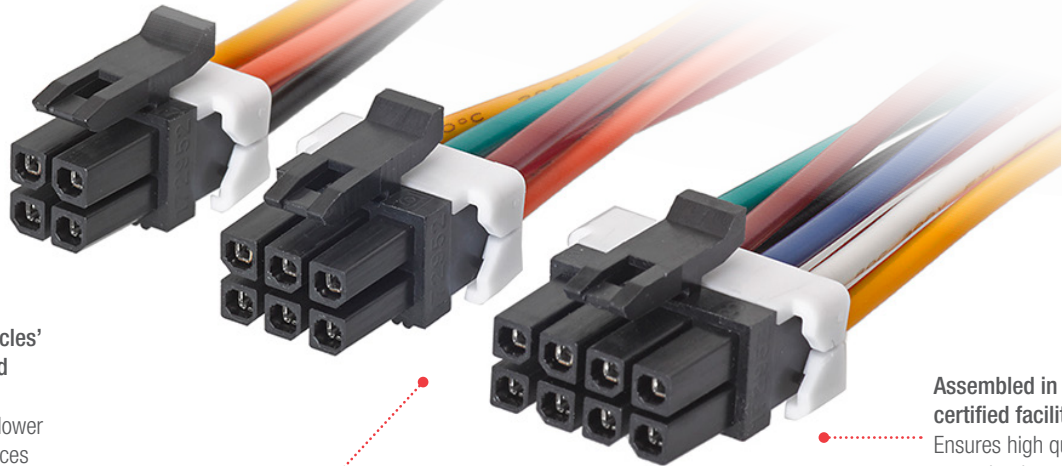

Micro-Fit TPA Receptacles' 5.0A current rating and 3.00mm pitch
Delivers a high-density, lower power connection. Reduces terminal back-out

Assembled in ISO/TS16949-certified facilities
Ensures high quality. Meets current automotive industry standards

Meets 2011/65/EU RoHS Compliance
Decreases engineering time and resources

Applications

Consumer / Home Appliance

- Harness manufacturers
- Appliances

Data / Computing

- Harness manufacturers
- Desktops
- Workstations
- Power supplies
- Uninterruptible Power Supply (UPS)

Telecommunications / Networking

- Harness manufacturers
- Servers
- Routers
- Switches

Automotive / Commercial Vehicle

- Harness manufacturers
- Non-sealed applications
- Inside devices

UL 1007 discrete wires (dual-row versions);
UL 1061 discrete wires (single-row versions)
Ready to use in electronic appliance applications. Provide ease of design, prototyping and production



Workstation



Refrigerator



Servers

Specifications

REFERENCE INFORMATION

Packaging:
 UL File No.: E29179
 CSA File No.: LR19980
 Mates With:
 Micro-Fit 3.0 Connectors
 Use With: Micro-Fit Headers
 Designed In: Millimeters
 RoHS: Yes
 Halogen Free: No
 Glow Wire Compliant: No

ELECTRICAL

Voltage (max.): 600V
 Current (max.): 5.0

MECHANICAL

Contact Insertion Force (max.): 14.7N per contact
 Contact Retention to Housing (min.): 24.5N
 Mating Force (max.): 8N per circuit
 Durability (max.): typically 30 cycles, refer to product specifications

PHYSICAL

Housing: Nylon
 Operating Temperature: -40 to +105°C

Ordering Information

| Series No. | Product | Circuits | Lengths |
|------------------------|---|----------|-----------------------------------|
| 45132 | Off-the-Shelf Micro-Fit Dual-Row TPA Discrete Wire Cable Assemblies | 4, 6, 8 | 150.00mm, 300.00mm and 1.0m |
| 145132 | Off-the-Shelf Micro-Fit Single-Row TPA Discrete Wire Cable Assemblies | 2 to 7 | 75.00mm, 150.00mm, 300.00mm, 1.0m |

| Custom Product | Description |
|----------------|--|
| Contact Molex | Micro-Fit Discrete Wire Cable Assembly, Custom Lengths and Other Options |

www.molex.com/link/otscableassemblies.html