


# blanking plug NPQH-P-S8-P10

Part number: 578259

FESTO

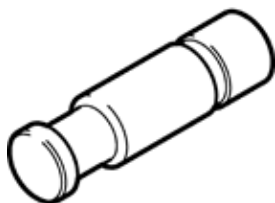

## Data sheet

Feature	Value
Size	Standard
Assembly position	Any
Container size	10
Operating pressure complete temperature range	-0.95 ... 20 bar
Certificate issuing department	NSF C0523185
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	3 - High corrosion stress
Food-safe	See declaration of conformity NSF/ANSI 169
Ambient temperature	0 ... 150 °C
Product weight	7.4 g
Pneumatic connection, port 1	Push-in sleeve QS-8
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass