

PRODUCT DATASHEET

HALOSTAR STARLITE 10 W 6 V G4

HALOSTAR STARLITE 2000 | Low-voltage halogen lamps with pin base



AREAS OF APPLICATION

- General illumination
- Entrance lighting
- Accent lighting
- Lighting for reading
- Garden lighting
- Shops
- Restaurants, hotels and similar prestigious applications
- Offices, public buildings
- Outdoor applications only in suitable luminaires

PRODUCT BENEFITS

- Brilliant accent light
- Incredibly small dimensions for revolutionary new luminaire designs
- Approved for use in open luminaires (to IEC 60598-1)
- Axial filament for optimum directional light
- Special pins for corrosion protection
- UV filter
- Contains no mercury

PRODUCT FEATURES

- Average life: 2,000 h
- 100 % dimmable
- Color rendering index R_a : 100

TECHNICAL DATA

Electrical data

Nominal wattage	10.00 W
Nominal voltage	6 V
Rated wattage	10.00 W
Power factor λ	1.00
Claimed equiv. conventional lamp power	10 W

Photometrical data

Nominal luminous flux	145 lm
Rated color temperature	2700 K
Light color (designation)	Warm White
Rated luminous flux	145 lm
Color rendering index Ra	100
Color temperature	2700 K
Luminous flux	145 lm
Color rendering index Ra	100

Light technical data

Starting time	0.0 s
Warm-up time (60 %)	0.00 s

Dimensions & weight



Diameter	10.0 mm
Overall length	33.0 mm
Light center length (LCL)	22.0 mm
Outer bulb	T10
Length	33.0 mm

Lifespan

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000

Additional product data

Base (standard designation)	G4
Mercury content	0.0 mg
Mercury-free	Yes

Capabilities

Burning position	Any
Dimmable	Yes


Certificates & standards

Energy consumption	11 kWh/1000h
Energy efficiency class	C

Country-specific categorizations

ILCOS	HSGS/C/AXUB-10-6-G4-10/22
-------	---------------------------

Light Distribution

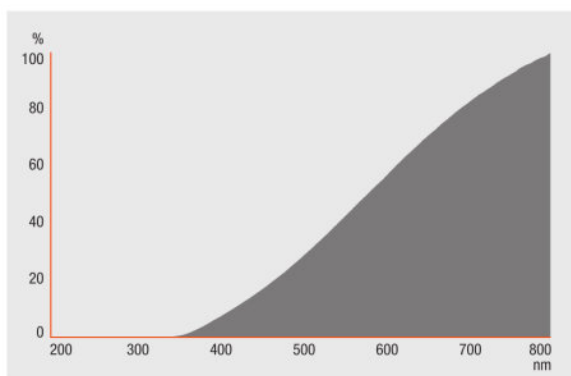

Spectral power distribution

LOGISTICAL DATA

Product code	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Gross weight	Volume
4058075094192	Folding carton box 1	25 mm x 23 mm x 70 mm	3.10 g	0.04 dm ³
4058075094208	Shipping carton box 40	144 mm x 107 mm x 121 mm	165.00 g	1.86 dm ³

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

DISCLAIMER

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.