


**KEMET Part Number: PMR205AC6470M100R30**  
(P405CE474M125AH101)

**KEMET**  
a YAGEO company

PMR205/P405, Film, Metallized Paper, Resistor/Capacitor, 0.47 uF, 20%, 250 VDC, 85°C, Lead Spacing = 20.3mm

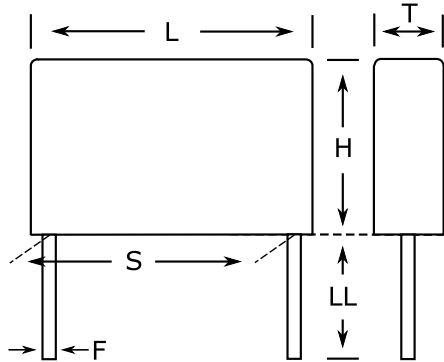

#### Dimensions

L	24mm MAX
H	14mm MAX
T	7.6mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

#### Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	250

#### General Information

Series:	PMR205/P405
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit not approved
RoHS:	Yes
Lead:	Wire Leads
AEC-Q200:	No
Construction:	Molded
Component Weight:	3.6 g
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 100 Ohms.

#### Specifications

Capacitance:	0.47 uF
Capacitance Tolerance:	20%
Voltage AC:	125 VAC
Voltage DC:	250 VDC
Temperature Range:	-40/+85°C
Rated Temperature:	85°C
Insulation Resistance:	2.128 GOhms
Safety Class:	X2

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.

**KEMET**  
a YAGEO company