


P410, Film, Metallized Paper, Resistor/Capacitor, 0.068 uF, 20%, 1000 VDC, 85°C, Lead Spacing = 20.3mm

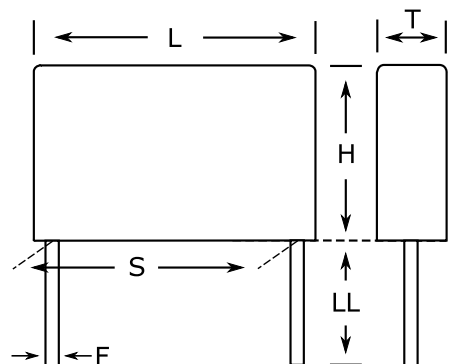

Dimensions

L	24mm MAX
H	16.5mm MAX
T	11.3mm MAX
S	20.3mm +/-0.4mm
LL	30mm +5mm
F	0.8mm +/-0.05mm

Packaging Specifications

Packaging:	Bulk, Bag
Packaging Quantity:	150

General Information

Series:	P410
Dielectric:	Metallized Paper
Style:	Radial
Features:	RC Unit approved
RoHS:	Yes
Lead:	Wire Leads
Qualifications:	ENEC, UL, cUL
AEC-Q200:	No
Construction:	Molded
Component Weight:	6.3 g
Miscellaneous:	Resistor Tolerance: +/-30%. Resistor= 100 Ohms.

Specifications

Capacitance:	0.068 uF
Capacitance Tolerance:	20%
Voltage AC:	300 VAC
Voltage DC:	1000 VDC
Temperature Range:	-40/+85°C
Rated Temperature:	85°C
Insulation Resistance:	3 GOhms
Safety Class:	X1