


BPK

Blind plates, plastic

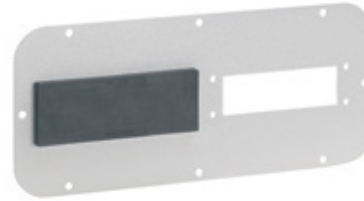

Product description

Blind plates close cutouts for standard 10-pole / 16-pole / 24-pole industrial connectors.

Plastic blind plates are available in two different versions:

Type BPK-R: Blind plates for snapping into metal sheet plates up to a thickness of 1.5 mm

Type BPK: Blind plates for screw connection

Advantages

- Fast mounting of the blind plates BP-R range by snapping into the cutout
- Integrated circular sealing

Specification

Material Polyamide (PA)
 Flame class BPK-R: UL94-Vo
 BPK: UL94-V2
 Temperature - 30°C to + 140°C (static)
 Properties Halogen-free, silicone-free

Type	Order No.	Blind plate for KEL cut-out	Dimensions	PU
BPK 10	42015	KEL 10 KEL-ER 10	103 × 52 mm	10
BPK-R 16	42006	KEL 16 KEL-ER 16	120 × 55 mm	10
BPK 16	42016	KEL-QUICK 16	124 × 52 mm	
BPK-R 24	42008	KEL 24 KEL-ER 24	147 × 55 mm	10
BPK 24	42024	KEL-QUICK 24	150 × 52 mm	
BPK - JFX	42620	KEL-JUMBO flex	88 × 88 mm	5

BPM

Blind plates, metal



Type	Order No.	Blind plate for KEL cut-out	Dimensions	PU
BPM-B	42013	KEL-B KEL-ER B KEL-QUICK B	75 × 58 mm	10
BPM-6	42011	standard 6-pole industrial connectors	90 × 52 mm	10
BPM-10	42014	KEL 10 KEL-ER 10	99 × 58 mm	10
BPM-FG B	42012	KEL-FG B	80 × 58 mm	10
BPM-16	42025	KEL 16 KEL-ER 16 KEL-QUICK 16	118 × 56 mm	10
BPM-24	42027	KEL-24 KEL-ER 24 KEL-QUICK 24	145 × 56 mm	10
BPM-24 20	42028	KEL-24 xx MT	147 × 102 mm	1
BPM-JUMBO flex	42033	KEL-JUMBO flex	88 × 88 mm	1
BPM-JUMBO 1	42030	KEL-JUMBO 1	116 × 110 mm	1
BPM-JUMBO 2	42032	KEL-JUMBO 2	200 × 116 mm	1
BPM-ULTRA	42633	KEL-ULTRA flex	∅ 168 mm Width: 1,5 mm	1

Product description

Blind plates to close cutouts for standard 6-pole / 10-pole / 16-pole / 24-pole industrial connectors.

Blind plates are supplied with a gasket.

Specification

Material Steel, zinc-plated
Width 2 mm