


Sockets

PKI 10 A

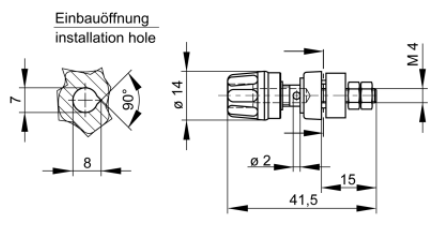

Product	PKI 10 A
description	Pole terminal with claw edge and captive insulated head and insulated ring. 4 mm diameter nickel-plated brass threaded bolt with 2 mm diameter transverse hole. For insulated, non-rotating installation in equipment chassis and switchpanels with a wall thickness up to 2 mm.
operating instruction	BA402
article-no. / *colour	9301031xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet  88 yellow green Ni
drawing	
technical data	
connection	M4 thread
rated voltage ⁽¹⁾	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽³⁾
rated current ⁽¹⁾ (consider derating curve)	35 A
material socket	brass, nickel plated
housing material	PF
temperature range acc. To IEC61010 ⁽²⁾	-25 °C to +100 °C
standard	IEC 61010

⁽¹⁾ for normal environmental conditions -5°C to +40°C

⁽²⁾ contact the manufacturer for applications at deviating temperature ranges

⁽³⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 03.09.2018