



PLS 008 MINI LED / PLS 013 MINI LED 230V 50/60Hz

Product specification

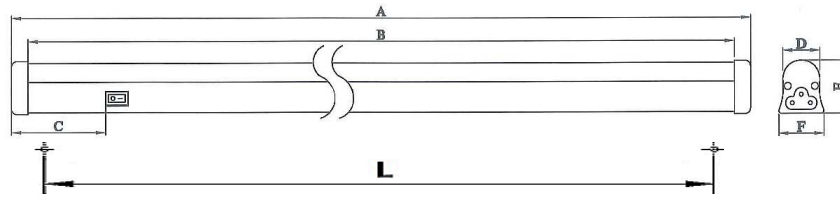


Type	Voltage(V)	Current(A)	Flux(lm)	A(mm)	B(mm)	C(mm)	D(mm)	E(mm)	F(mm)	L(mm)
PLS 008 MINI LED	230	0.020	324	300.0	282.6	50.0	19.6	28.0	23.9	< 280
PLS 013 MINI LED	230	0.033	612	530.0	512.6	50.0	19.6	28.0	23.9	< 510

Circuit Diagram

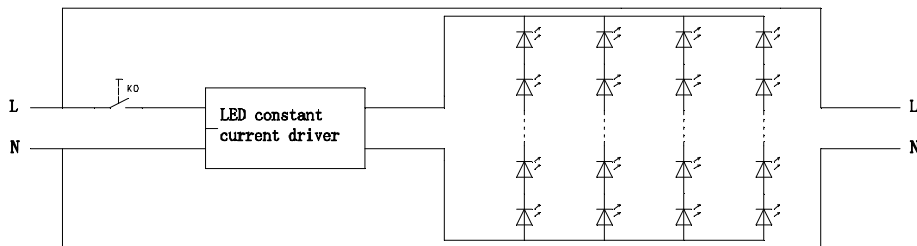

Installation


Method 1: Drill two holes on the cabinet and use the screw driver for cross head to fix the clamps. Then install the lamps and mains connector (cable length is 1.8m).

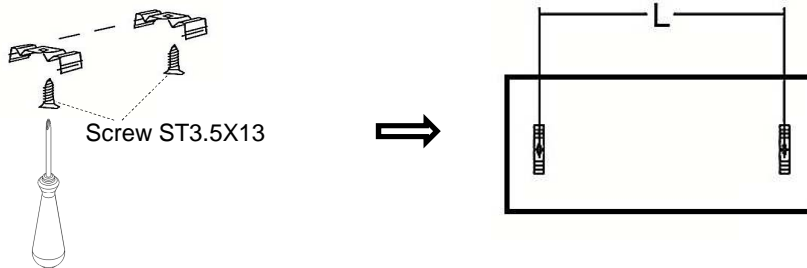

Method 2: Peel off back paper from magnetic strip. Paste the magnet on the lamps. Then install the lamps and mains connector (cable length is 1.8m).



Option: Lamps can be wired up with the connector provided.

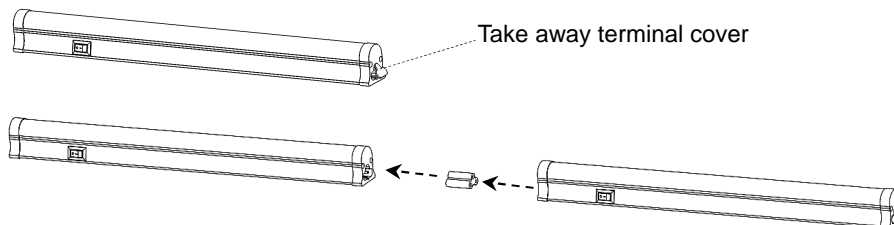

Pfannenberg GmbH
 Werner-Witt-Straße 1
 D- 21035 Hamburg 1
 Tel.: +49/ (0)40/ 734 12-0 .
 Fax: +49/ (0)40/ 734 12-101
<http://www.pfannenberg.com>

