


## DIMMER

### paladin 873 040 led

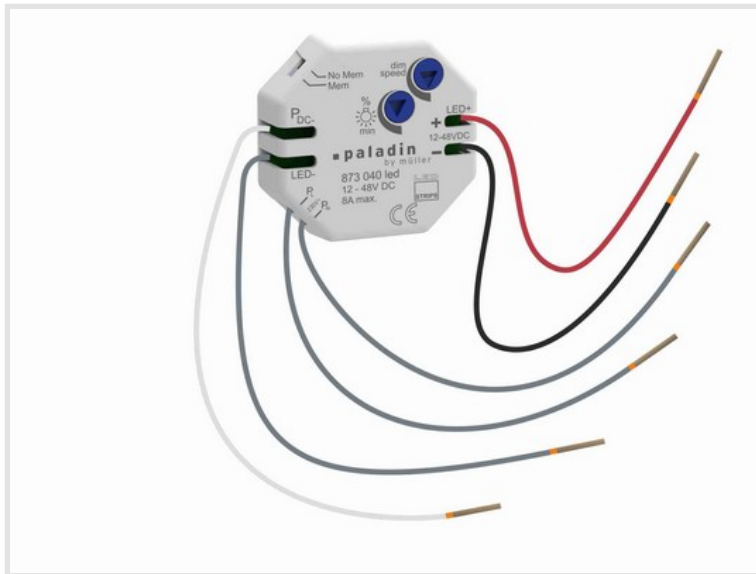

#### Overview

- Dimmer for LED lamps 12 - 48 V DC up to 8 A, with Pulse Width Modulation technology (PWM), specially designed for 1-channel LED strips
- Flush-mounted fitting
- Minimum dimming-value adjustable
- Dimming speed adjustable
- For pushbuttons
- Installation in standard boxes behind a pushbutton possible
- Small design (13 mm)
- Easy to connect
- Memoryfunction of the last dimming value
- Protection against overload, short circuit and overheat
- Easy to connect (10 cm litz wires with ferrules)

#### Order numbers

■ **paladin**

873 040 led for LED strips

Technische Änderungen vorbehalten.

# DIMMER

## paladin 873 040 led

### Technical data

Supply voltage	12-48 V DC
Power consumption	0,5 VA
Dimensions	46 x 42 x 13 mm
Mounting	Flush-mounting
Permitted ambient temperature	0° ... +40°C
Type of protection	IP 20 to DIN EN 60529
Type of lamps	dimmable LED strips
Types of load	LED
Dimmable 12-48 V DC LED strips	8 A

Technische Änderungen vorbehalten.

