


## DIMMER

### paladin 873 030 led

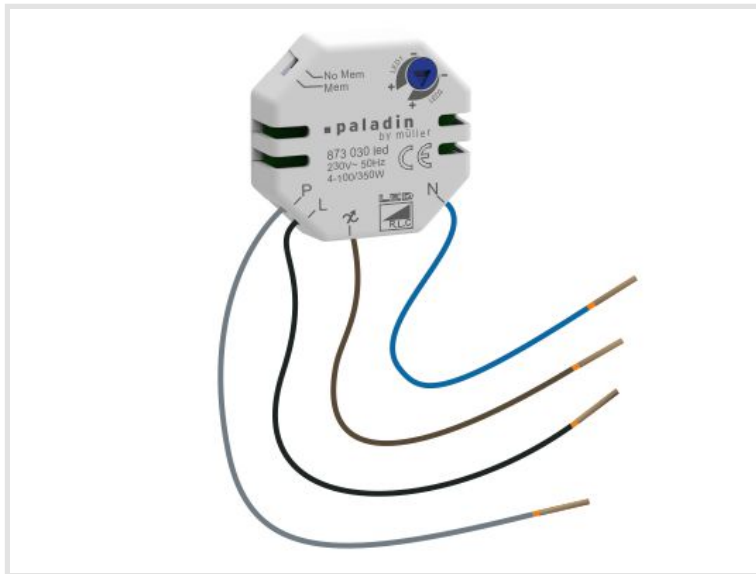

#### Overview

- Universal dimmer for dimmable LED-Lamps for leading edge dimming OR dimmable LED
- lamps with electronic transformer for trailing edge dimming
- Flush-mounted fitting
- Minimum dimming-value adjustable
- For pushbuttons
- Installation in standard boxes behind a pushbutton possible
- Small design (13 mm)
- Easy to connect
- Memoryfunction of the last dimming value
- Softstart function
- Protection against overload, short circuit and overheat
- Easy to connect (10 cm litz wires with ferrules)

#### Order numbers

##### ■ paladin

873 030 led for LED loads:  
4 - 100 / 350 W

Technische Änderungen vorbehalten.

# DIMMER

## paladin 873 030 led

### Technical data

Supply voltage	230 V 50 Hz
Power consumption	2 VA
Dimensions	46 x 42 x 13 mm
Mounting	Flush-mounting
Permitted ambient temperature	0°...+40°C
Type of protection	IP 20 to DIN EN 60529
Type of lamps	dimnable LED lamps
Glow lamp load	max. 1,5 mA
Types of load	LED
Dimmable 230 V~ LED lamps (leading edge dimming)	4–100 W
Dimmable 230 V~ LED lamps (trailing edge dimming)	4–350 W
Dimmable 12 V~ LED lamps (trailing edge dimming) with electronic transformer, type C	1 lamp per transformer max. 6 transformers (50 W)

Technische Änderungen vorbehalten.

