


PeakTech® TF-55 PROD-ID: P TF-55

[BACK](#)

Universal-Temperature-Probe, -50...+300 °C

Universal temperature probe suitable for liquids, surface and air measurements. This temperature probe is typ-K-thermocouple (NiCrNi). This probe is suitable for all of our thermometers published in our catalogue.

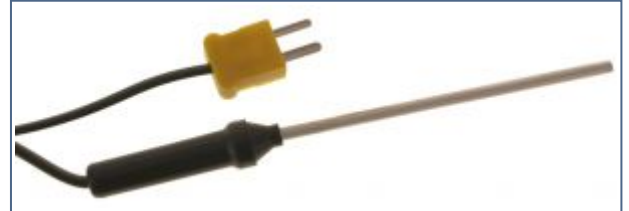

PICTURE

[TF-55.jpg \(56.8 kB\)](#)

Model	P TF-55
Range	-50 °C...+300 °C / -58 °F...+572 °F
Accuracy	±2,5%
Cable length	70 cm
Probe length	75 mm
Probe	3,0 mm
EAN-13	4250569402074

